


Timing Pulleys XL

(0.200" / 5.08mm pitch)
for 9.53mm (3/8") wide belt
Centre drilled or Pilot Bore
in Aluminium with Zinc plated Steel Flanges

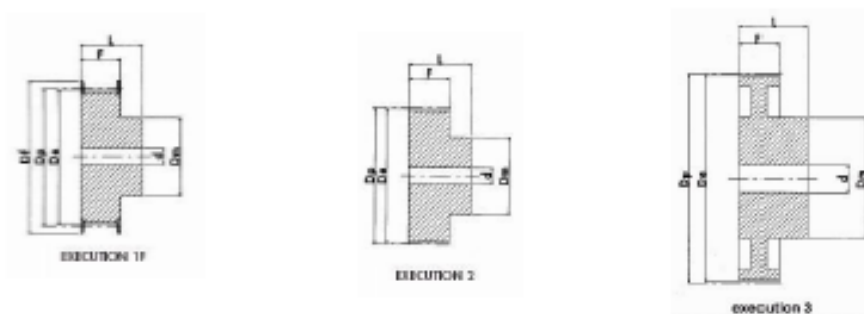

Dimensions

Please note : All dimensions subject to change.

Pulleys may be Bored or Unbored.

If a dimension is critical to your application please contact our sales department for confirmation.
for [special pulleys](#) or [reworked](#) pulleys please contact our manufacturing department

Code	Type	No. Teeth	Dp	De	Df	Dm	F	L	Bore	No. Flanges
P10XL037F	1F	10	16.17	15.66	23	9.5	14.3	20	-	2
P11XL037F	1F	11	17.79	17.28	23	9.5	14.3	20	-	2
P12XL037F	1F	12	19.40	18.90	25	10	14.3	20	-	2
P13XL037F	1F	13	21.02	20.51	25	10	14.3	20	-	2
P14XL037F	1F	14	22.64	22.13	28	15	14.3	20	-	2
P15XL037F	1F	15	24.26	23.75	28	15	14.3	20	-	2
P16XL037F	1F	16	25.87	25.36	32	16	14.3	20	-	2
P17XL037F	1F	17	27.49	26.98	32	20	14.3	20	-	2
P18XL037F	1F	18	29.11	28.60	35	20	14.3	20	-	2
P19XL037F	1F	19	30.72	30.22	35	20	14.3	22	-	2
P20XL037F	1F	20	32.34	31.83	38	23.5	14.3	22	-	2
P21XL037F	1F	21	33.96	33.45	38	23.5	14.3	22	-	2
P22XL037F	1F	22	35.57	35.07	41	25	14.3	22	6	2
P24XL037F	1F	24	38.81	38.30	44	30	14.3	22	6	2
P26XL037F	1F	26	42.04	41.53	48	30	14.3	22	8	2
P27XL037F	1F	27	43.66	43.15	48	30	14.3	22	8	2
P28XL037F	1F	28	45.28	44.77	51	34	14.3	22	8	2
P30XL037F	1F	30	48.51	48.00	54	38	14.3	22	8	2
P32XL037F	1F	32	51.74	51.24	57	38	14.3	25	8	2
P34XL037F	1F	34	54.98	54.47	61	38	14.3	25	8	2
P35XL037F	1F	35	56.60	56.09	61	38	14.3	25	8	2
P36XL037	2	36	58.21	57.70	-	45	14.3	25	8	0
P38XL037	2	38	61.45	60.94	-	45	14.3	25	8	0
P40XL037	2	40	64.68	64.17	-	45	14.3	25	8	0
P42XL037	2	42	67.91	67.41	-	45	14.3	25	8	0
P44XL037	2	44	71.15	70.64	-	45	14.3	25	8	0
P48XL037	3	48	77.62	77.11	-	45	14.3	25	10	0
P60XL037	3	60	97.02	96.51	-	45	14.3	25	10	0
P72XL037	3	72	116.42	115.92	-	45	14.3	25	10	0