


DX06WY012B Datasheet

Product Name // DX06WY012B, 6mm Diameter, Wire Leads 200mm, Yellow, 12V, Black Plated Brass

 [View Product Page](#)

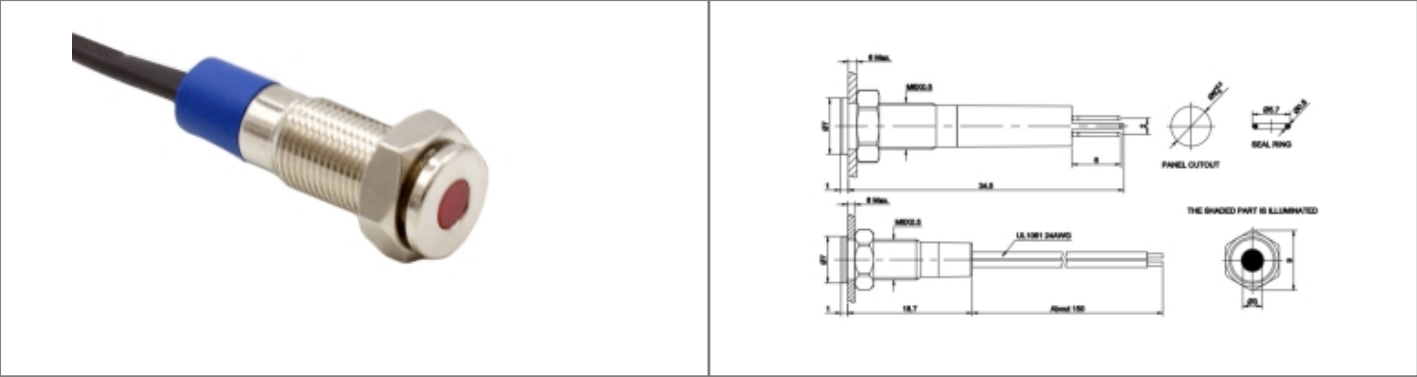

// Product Description:

- | | |
|--|--|
|  DX Series |  Yellow |
|  6mm Diameter |  12V |
|  Wire Leads 200mm |  Black Plated Brass |

// General Information:

Product Display Title:	6mm Vandal Resistant Indicator DX Range
Product Family:	Indicators
Product Series:	6mm Vandal Resistant Indicator DX Range
Bezel Finish:	Gloss
Body Colour:	Black
Body Material:	Brass
Body Material Type:	Metal
Diameter:	6mm
Dielectric Withstanding Voltage:	1500V
Function:	Vandal Resistant Indicator
Illumination Colour:	Yellow
Illumination Voltage:	12V
Indicator Profile:	Flat-round
Insulation Resistance:	≥100MΩ(500VDC)
Ip Rating:	IP67
Material Finish:	Gloss
Max Operating Temperature:	55°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6mm
Panel Cut Out:	6mm Diameter circle
Rohs Compliant:	Yes
Thread Size:	M6 X 0.5

// Product PDF Links

 [6mm & 8mm Vandal Resistant...](#)

// Product 3D CAD Model Links

 [DX06WY012B3D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)