



ENGLISH

Datasheet  
Stock No. 124-4132  
RS PRO LCD Smart Soldering Station 60W




**Specifications:**

<b>Model Number</b>	<b>124-4132</b>
<b>Plug type</b>	<b>B and C</b>
<b>Primary Application Category</b>	<b>Soldering</b>
<b>Input Voltage</b>	<b>220V ~240V</b>
<b>Output Power</b>	<b>60W</b>
<b>Maximum Operating Temperature</b>	<b>480 °C</b>
<b>Minimum Operating Temperature</b>	<b>200 °C</b>
<b>Number of Outputs</b>	<b>2 (Iron and USB output)</b>
<b>Display Type</b>	<b>LCD</b>

Nov/2016

<b>ESD Safe</b>	<b>10<sup>6</sup>~10<sup>10</sup></b>
<b>Height</b>	<b>106mm</b>
<b>Width</b>	<b>150mm</b>
<b>Depth</b>	<b>180mm</b>
<b>Weight</b>	<b>1.75kg</b>

#### **EU B & C type plug**

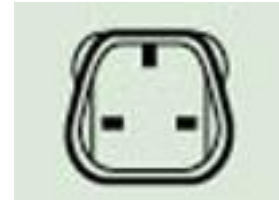

#### **Features:**

**Temperature reading can be changed to Fahrenheit or Centigrade**

**Temperature calibration function**

**Auto sleep and wake, system lock, and tip calibration functions**

**Large screen with backlight**

**LCD brightness and contrast are adjustable**

**Designed with functional scroll temperature control dial for easy setting**

**Comes with high end alumina ceramic heating element for fast heat recovery**

**With inbuilt data storage memory, store and recall 3 frequently used temperatures**

**USB 5V/1A power output**

**Built-in DC 5V/1A USB port for power supply**

**Separate iron stand**

**Complies with CE & ESD standards. RoHS Compliant.**