

Miniature Quick Wire Thermocouple Socket

Features


- Easy jab-in connection
- Just push in wire & tighten screw
- Contacts are polarised to prevent incorrect termination



Specification

Thermocouple Type	K
Connector Size	Miniature
Connector Type	Quick Wire Socket
Colour	Green
Max. Temperature	220 °C
Pins	Solid Round Pins
+Positive Contact	Nickel Chromium
-Negative Contact	Nickel Alloy
Standards Met	BS EN 50212:1997. RoHS

Drawing

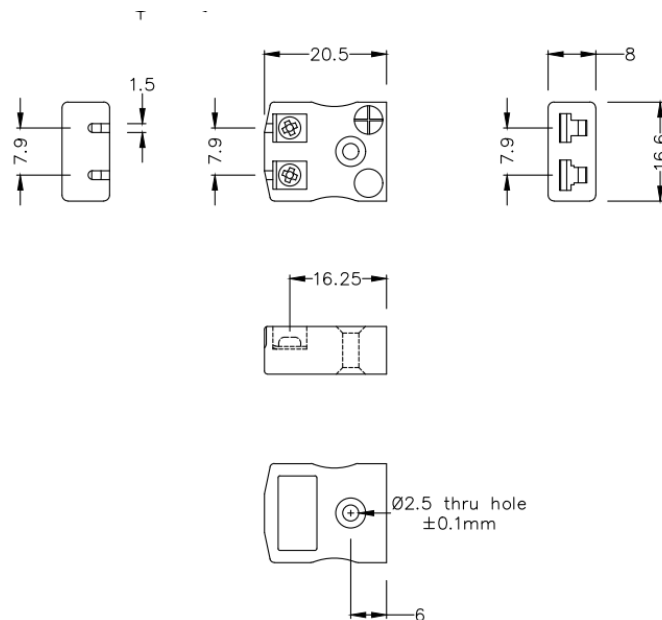

Miniature in-line Socket - Quick Wire
(dimensions in mm)

Art. Nr.
RND 410-00072