

Datasheet

Rotary Switch

RS Stock number 734-7369



SPECIFICATIONS

ELECTRICAL RATING: 0.5A 24VDC; 0.2A 48VDC

CONTACT RESISTANCE: 100mΩ MAX.

INSULATION RESISTANCE: 100MΩ MIN. 500VDC

DIELECTRIC STRENGTH: Breakdown is not allowable;
500VAC for 1 minute

OPERATING FORCE: 350±100g

OPERATING LIFE: 2,000 cycles

OPERATING TEMPERATURE RANGE : -20°C ~ 70°C

MATERIAL



HOUSING: NYLON 6/6

BASE: LCP

ACTUATOR: NYLON 6/6

TERMINAL: Brass gold plating.

Dimensions – inch
mm

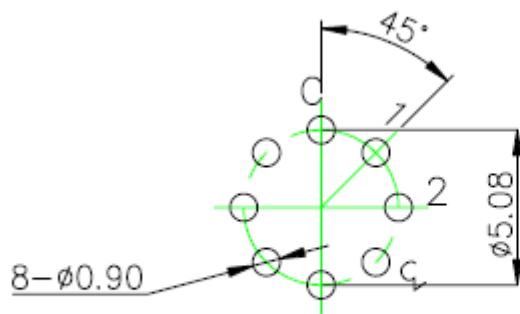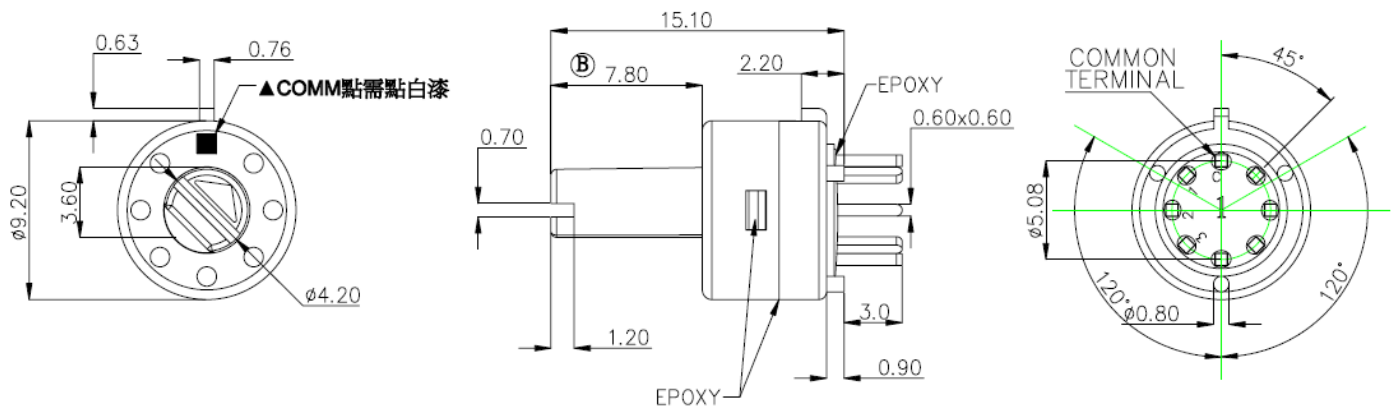

P.C.B. LAYOUT

Ⓐ

TRAVEL	SWITCH POSITION
45°	C-1
90°	C-2
135°	C-3