


Geberit Mapress Copper T-piece with female thread

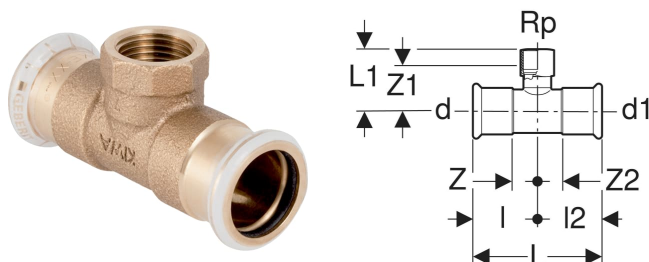

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water $\leq 120\text{ }^{\circ}\text{C}$
- For service water and process water
- For compressed air (oil purity class 0–3)

- For negative pressure
- For inert gases (e.g. nitrogen)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed

- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

TECHNICAL DATA

Product material Gunmetal / lead-free gunmetal

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	Product material	arc °	L cm	L1 cm	I cm	I2 cm	Z cm	Z1 cm	Z2 cm
61352	10 / 15 / 10	12	1/2	12	Gunmetal	90	6.8	2.4	3.4	3.4	1.7	1.1	1.7
61354	12 / 15 / 12	15	1/2	15	Lead-free gunmetal	90	6.8	2.6	3.4	3.4	1.4	1.3	1.4
61355	15	18	1/2	18	Gunmetal	90	8.2	2.4	4.1	4.1	2.1	1.1	2.1
61357	20 / 15 / 20	22	1/2	22	Lead-free gunmetal	90	8.4	2.6	4.2	4.2	2.1	1.3	2.1
61395	20	22	3/4	22	Gunmetal	90	9	2.7	4.5	4.5	2.4	1.2	2.4

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	Product material	arc °	L cm	L1 cm	I cm	I2 cm	Z cm	Z1 cm	Z2 cm
61359	25 / 15 / 25	28	1/2	28	Lead-free gunmetal	90	8.8	2.9	4.4	4.4	2.1	1.6	2.1
61360	25 / 20 / 25	28	3/4	28	Gunmetal	90	8.4	3.5	4.2	4.2	1.9	2	1.9
61362	32 / 15 / 32	35	1/2	35	Gunmetal	90	10	3.5	5	5	2.4	2.2	2.4
61366	40 / 15 / 40	42	1/2	42	Gunmetal	90	11.4	3.8	5.7	5.7	2.7	2.5	2.7
61370	50 / 15 / 50	54	1/2	54	Gunmetal	90	13.8	4.4	6.9	6.9	3.4	3.1	3.4