


Product data sheet

Characteristics

AZ5CE010

single conductor insulated cable end - medium
- 1 mm² - red

Product availability: Non-Stock - Not normally stocked in distribution facility

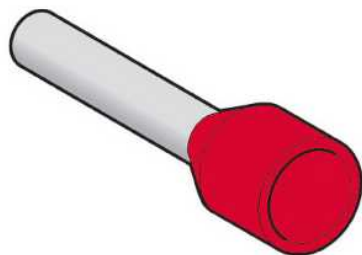

Main

| | |
|---------------------------|----------------------------------------|
| Commercial Status | Commercialised |
| Range of product | Cable ends |
| Product or component type | Cable end |
| Cable end size | Medium |
| Standards | NF C 63-023 |
| Type of packing | Dispenser pack |
| Quantity per set | 5 sets of 200 |
| Cable cross section | 0 in ² (1 mm ²) |

Complementary

| | |
|------------------------|-------------------------------|
| Cable end type | Single conductor |
| Additional information | Without marker tag holder |
| Colour | Red |
| Bezel material | Halogen-free plastic |
| Tube material | Copper conforming to ISO 1337 |
| Number of cables | 1 |
| AWG gauge | 18 |
| Bezel size | Ø 3.4 mm |
| Tube diameter | 0.07 in (1.8 mm) |
| Length | 0.53 in (13.5 mm) |
| Tube length | 0.32 in (8.2 mm) |
| CAD overall width | 0.12 in (3 mm) |
| CAD overall height | 0.12 in (3 mm) |
| CAD overall depth | 0.55 in (14 mm) |
| Product weight | 0.36 lb(US) (0.165 kg) |

Environment

| | |
|---------------------------------------|----------------------------|
| Product certifications | UL |
| Ambient air temperature for operation | -4...221 °F (-20...105 °C) |

Ordering and shipping details

| | |
|-----------------------|-----------------------------------------------------------|
| Category | 22621 - IEC PANEL ACCESSORIES |
| Discount Schedule | I |
| Nbr. of units in pkg. | 1000 |
| Package weight(Lbs) | 0.01 |
| Product availability | Non-Stock - Not normally stocked in distribution facility |
| Returnability | N |
| Country of origin | FR |

Contractual warranty

| | |
|--------|-----------|
| Period | 18 months |
|--------|-----------|