




FAG

SES210-L

Plummer block housing




Split plummer block housing for various bearing designs. The SNV series will be replaced by the new SES series in 2022.

Technical information

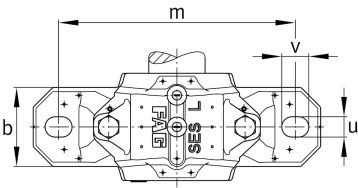

Main Dimensions & Performance Data

D	90 mm	Outside diameter bearing
a	205 mm	Length base
h 1	113 mm	Height
g	90 mm	Width housing body
K	41 mm	Width bearing seat
≈m	3.08 kg	Weight

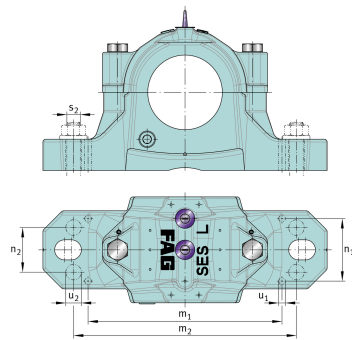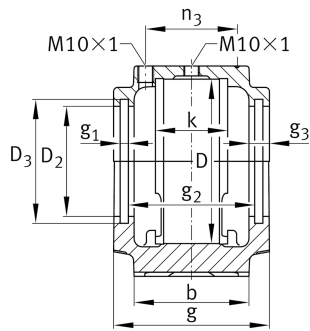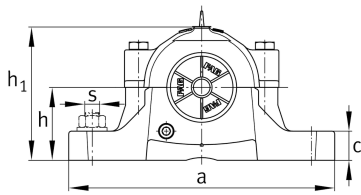

Dimensions

b	60 mm	Width base
c	25 mm	Height base
h	60 mm	Base to shaft centerline height
m	170 mm	Distance fixing bore
s	12.7 mm	Screw size
s	M12	Size of fixing screws
u	15 mm	Width slot
v	20 mm	Length slot
D 2	72 mm	Diameter sealing
D 3	80.5 mm	Diameter sealing groove
D 5	78.2 mm	Outside diameter sealing labyrinth
g 1	5 mm	Width sealing groove
g 2	72 mm	Distance sealing
g 3	12 mm	Wall thickness
g 4	34 mm	Distance oil lubrication
m 1	140 mm	Distance holes aligned pins m1
n 3	54 mm	Distance lubrication
n 4	76 mm	Distance lubrication sealing
u 1	6 mm	Bore diameter u1
u 2	11 mm	Bore diameter u2