


# Datasheet

## RS Pro Temperature Probe, K +750 °C With SYS Calibration

RS Stock No.343-0224

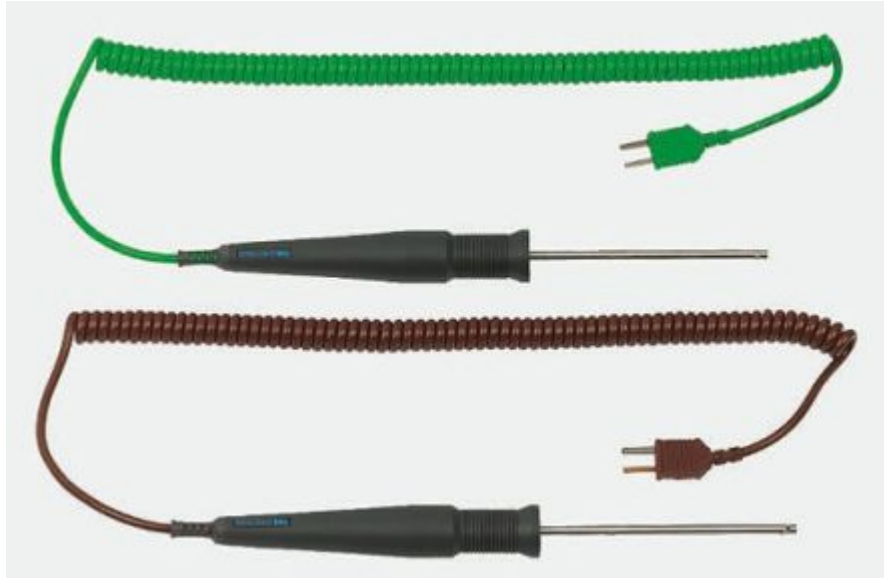

**These air probes feature an exposed thermocouple junction protected by a stainless steel sheath. It is perforated to allow the free passage of gases across the sensing element**

**The thermocouple junction is isolated from the sheath**

Sensor Type	K
Probe Type	Air, General
Probe Length	110mm
Probe Diameter	4mm
Maximum Temperature Measurement	+750 °C
Cable Length	2m
Best Accuracy	±0.25 %
Connector Type	Miniature Plug
Calibrated	SYSCAL