


1748-N2D


Nylon cable ties, black, UV resistant

CE

Material: polyamide PA 6.6 + carbon black
 Self-extinguishing class: UL 94-V2
 Working temperature: -40 °C ÷ +85 °C
 Minimum installation temperature: -10 °C
 Resistance to chemicals: Good resistance to bases, oils, greases, chloride solvents. Limited resistance to acids. Not resistant to phenols
 Reference standards: EN 62275:2015-02
 Classification: type 1 (EN)

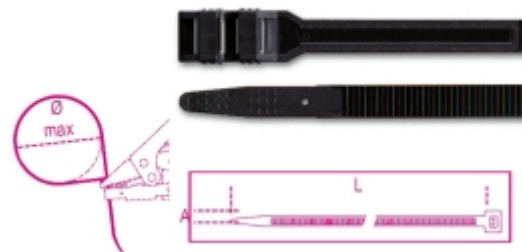

Please indicate number of cable ties, and not of packages, in your order

	art.	A mm	L mm	Ø MAX mm	F MAX N
					
BMN1890	BMN1890	9.0	180	40	400
BMN2690	BMN2690	9.0	265	62	540
BMN3690	BMN3690	9.0	360	93	540