

Features

- Well suited for work in confined spaces
- Clamping width: 10-140 mm
- Clamping depth: 85 /120 mm

RS PRO SCISSORS TYPE PULLER 10~140MM

0286444



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *Adjustable scissor jaws for various clamping width and depth.*
- *For removing bearings, gears, sprockets in hard-to-reach spaces.*
- *Particularly suitable for industry, agriculture and DIY.*
- *The scissor design makes jaws grip automatically.*
- *Scissor joint increases clamping force when pulling.*


General Specifications

Operation	Gear
Maximum Load	3.5T (Tonnes)
Puller Type	Bearing Puller
Clamping Width	10-140mm
Clamping Depth	85 / 120mm
Drive (Hex)	17mm
Spindle size	M17 X 190mm
Number of legs	2
Weight	1.02 Kg

Crossed Jaw



Uncrossed Jaw

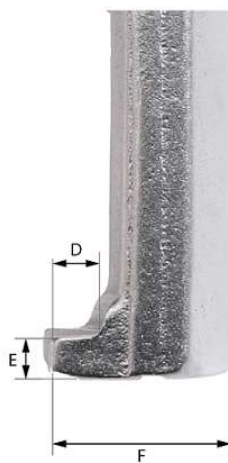

A	B	C	D	E	F
10~140mm	H17x190mm	31mm	5mm	3.5mm	10mm