

Housing - HC-HPR-B24-BFH-EMR-BK - 1411055

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON B24 panel mounting base, HPR series, for screw locking, for increased environmental and EMC requirements



Key commercial data

Packing unit	1 pc
GTIN	 4 046356 921688
Weight per Piece (excluding packing)	22.22 g
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	20 mm
Width	58 mm
Length	192 mm
Length of the assembly cutout	108 mm
Width of the assembly cutout	35 mm

Ambient conditions

Degree of protection of housing (IP)	IP68 (0.5 bar, 24 h)
	IP69K
Ambient temperature (operation)	-40 °C ... 125 °C

General

Note	For contact inserts HC-B24, BB46, D64, DD108, M
Type	B24
Housing type	Panel mounting base

Housing - HC-HPR-B24-BFH-EMR-BK - 1411055

Technical data

General

Locking type	for M6 screws
Torque	4 Nm (Locking screw)
Screw connection	none
Housing material	Aluminum die-cast
Housing surface material	Powder-coated, black
Seal material	NBR
Material lock	High-grade steel
Material of locking screw	High-grade steel

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261203
eCl@ss 8.0	27440202

ETIM

ETIM 4.0	EC000437
ETIM 5.0	EC000437

Approvals

Approvals

Approvals

EAC / GL

Ex Approvals

Approvals submitted

Approval details

 
EAC

GL


Drawings

Housing - HC-HPR-B24-BFH-EMR-BK - 1411055

Dimensioned drawing



Dimensioned drawing

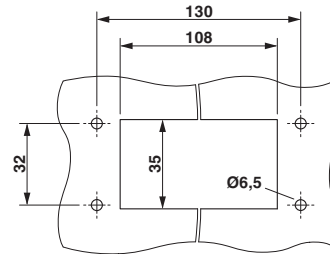

Dimensional drawing

Panel cutout