



Brand of NTN corporation


Technical data

BB20UU

Standard ball bushings closed



VISUAL (S)

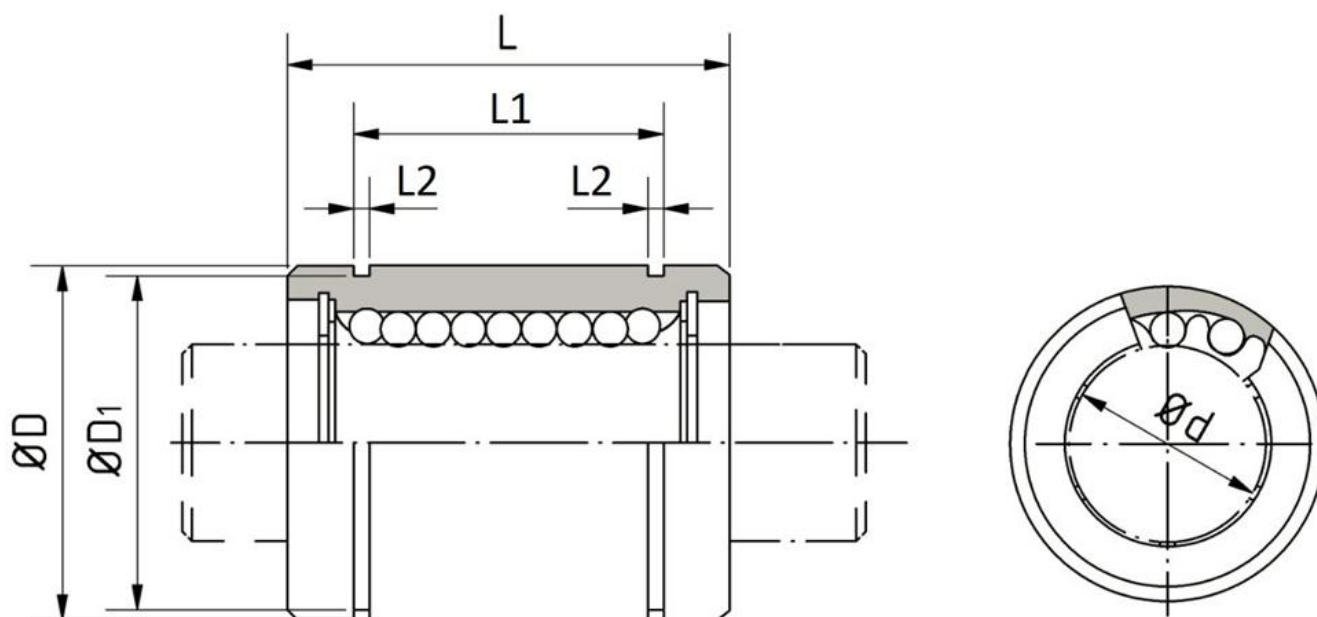

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	JIS dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	20 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0/-0,010
D - External diameter	32 mm
D - External diameter tolerance	0/-0,016
L - Length	42 mm
L - Length tolerance	0/-0,2
L1	30,5 mm
L1 tolerance	0/-0,2
D1 - Diameter	30,5 mm
L2	1,6 mm
Number of ball rows	5
Mass	0,1 kg

PRODUCT PERFORMANCE	
Cmin	0,792 kN
Cmax	1,159 kN
C0min	1,37 kN
C0max	2,004 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BB20UU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

