

Label, white, thermal transfer print, 50.00mm, 100m

Art.-No. 596-03116 | TAGR50TD1-1213-WH | 




- Pipe, warehouse and shelving label
- Supplied on a continuous roll and cut by hand or automated with printer cutters
- Also for rough surfaces
- Good resistance in outdoor applications



More products in this product group:


[Warehouse and pipe labelling, thermal transfer >](#)

Application	These coloured labels are used to identify storage systems with barcode and location information. They are also suitable for general marking of parts and components, samples and blocked goods in quality assurance, storage boxes and barrels.
Chem. Material Properties	Resistant to water, alcohol, most oils, greases, fuel, aliphatic solvents, weak acids, salts and alkalis.
Colour	White gloss (GSWH)
Material	Type 1213, Vinyl, glossy colours (1213)
Mech. material properties	Due to its flexibility and adhesiveness the material is also suitable for rough surfaces.
PART DESCRIPTION	TAGR50TD1-1213-WH
Pack Content	100 m
Package Content packed in	carton
Product Family	Helatag 1213
Product Group	Warehouse and pipe labelling, thermal transfer
Self adhesive (Yes/No)	Yes
Type	TAGR50TD1

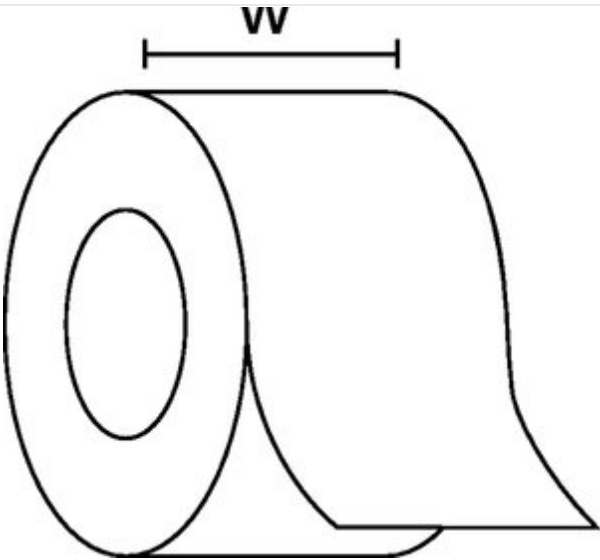

Print Method	thermal transfer print
Print Method (Alternative)	laser beam print
Thickness (T)	66.0 µm
Thickness of Foil	95
Thickness of foil test method	ISO 534
Width (W)	50.00 mm
Width of Liner (WL)	50.00 mm

Adhesive	Acrylic
Curing Temperature	from +8 °C
ELV compliant (Article 4 - 2)	YES
Halogen-free	No
Hazardous Goods	No
Initial tack	16 N/25 mm
Initial tack	FINAT FTM 1
Operating Temperature	-40 °C to +90 °C
Peel strength	27 N/15 mm
Peel strength test method	DIN 53455-5
Pre-Printed	No
ROHS compliant	Yes
Recommended Ribbon Type	TT822OUT
Shear strength	1.5
Shear strength test method	DIN 53455-5
Shelf Life	Minimum 1 year upon receipt / maximal 2 years after production date.
Specifications	RoHS ✓
UV-Stabilised	Yes

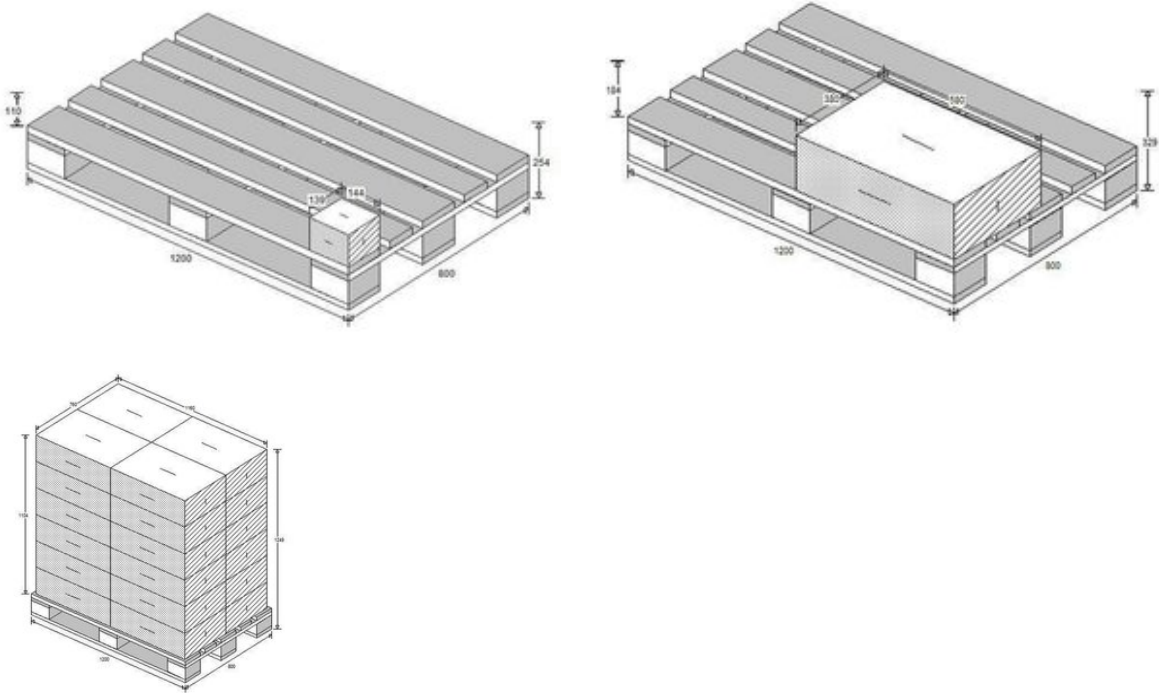

GTIN-13 / EAN	4031026690254
Labels per Column	1
Labels per Row	1 pc.
Packaging 1 - Height (m)	0.05 m
Packaging 1 - Length (m)	0.147 m
Packaging 1 - Qty	50
Packaging 1 - Type	reel
Packaging 1 - Volume (m³)	0.00108045 m³
Packaging 1 - Weight (kg)	0.676 kg
Packaging 1 - Width (m)	0.147 m
Packaging 2 - Height (m)	0.12 m
Packaging 2 - Length (m)	0.156 m
Packaging 2 - Qty	100
Packaging 2 - Type	carton
Packaging 2 - Volume (m³)	0.0028 m³
Packaging 2 - Weight (kg)	1.452 kg
Packaging 2 - Width (m)	0.15 m
Packaging 3 - Height (m)	0.184 m
Packaging 3 - Length (m)	0.58 m
Packaging 3 - Type	box

Packaging 4 - Length (m)	1.2 m
Packaging 4 - Type	pallet
Packaging 4 - Width (m)	0.8 m
Reel Length	50.00 m
Storage Temperature	+21 °C
Storage conditions	50% relative humidity., The storage in the original packaging is recommended., Please avoid warehousing under impacts such as high humidity, heat and coldness.

More Information

UNSPSC Key	39121702
------------	----------