

# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Connection technology carrier, fully assembled with FKCN 2x 18-pos., cover and release lever, incl. fitted cover, corresponding header: 1x CCDN 2,5/18-G1 P26 THR (1734436)

## Your advantages

- Tool-free mounting
- Available in 40 mm overall width
- Flammability rating V0 in accordance with UL 94
- Variety of connection technology
- Can be mounted on the DIN rail
- With DIN-rail-mountable bus connector and power connector system as an option

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 2202053       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | ACH           |
| Product key                          | ACHEAB        |
| GTIN                                 | 4046356980364 |
| Weight per piece (including packing) | 103 g         |
| Weight per piece (excluding packing) | 103 g         |
| Customs tariff number                | 85366990      |
| Country of origin                    | DE            |

# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

## Technical data


### Notes

|               |   |
|---------------|---|
| Assembly note | Please observe the application note in the download area. |
|---------------|---|

### Product properties

|                              |  |
|------------------------------|--|
| Product type                 | Upper housing part   |
| Housing type                 | DIN rail housing   |
| Housing series               | ME PLC   |
| Max. number of positions     | 36 (pitch: 5 mm)   |
| Type                         | Set consisting of upper housing part and connection technology |
| Ventilation openings present | no   |

### Dimensions
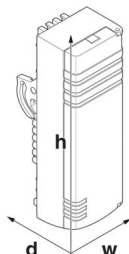
|                     |  |
|---------------------|--|
| Dimensional drawing |  |
| Width               | 39.7 mm  |
| Height              | 128 mm   |
| Depth               | 48.3 mm  |

### Material specifications

|  |                       |
|--|-----------------------|
| Color (Housing)                        | light gray (RAL 7035) |
| Flammability rating according to UL 94 | V0                    |
| CTI according to IEC 60112             | 225                   |
| Housing material                       | PC                    |
| Surface characteristics                | untreated             |

### Environmental and real-life conditions

#### Ambient conditions

|   |  |
|---|--|
| Max. IP code to attain                  | IP20   |
| Ambient temperature (operation)         | -40 °C ... 105 °C (depending on power dissipation) |
| Ambient temperature (storage/transport) | -40 °C ... 70 °C                                   |
| Ambient temperature (assembly)          | -5 °C ... 100 °C                                   |
| Relative humidity (storage/transport)   | 95 %   |

### Mounting

|               |                                  |
|---------------|----------------------------------|
| Mounting type | Latching with lower housing part |
|---------------|----------------------------------|

# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

## Packaging specifications

|                      |                     |
|----------------------|---------------------|
| Type of packaging    | packed in cardboard |
| Outer packaging type | Carton              |


# ME PLC 40 CT36 GY7035 VPE1 - Front connection module

2202053

<https://www.phoenixcontact.com/in/products/2202053>

## Drawings

Dimensional drawing

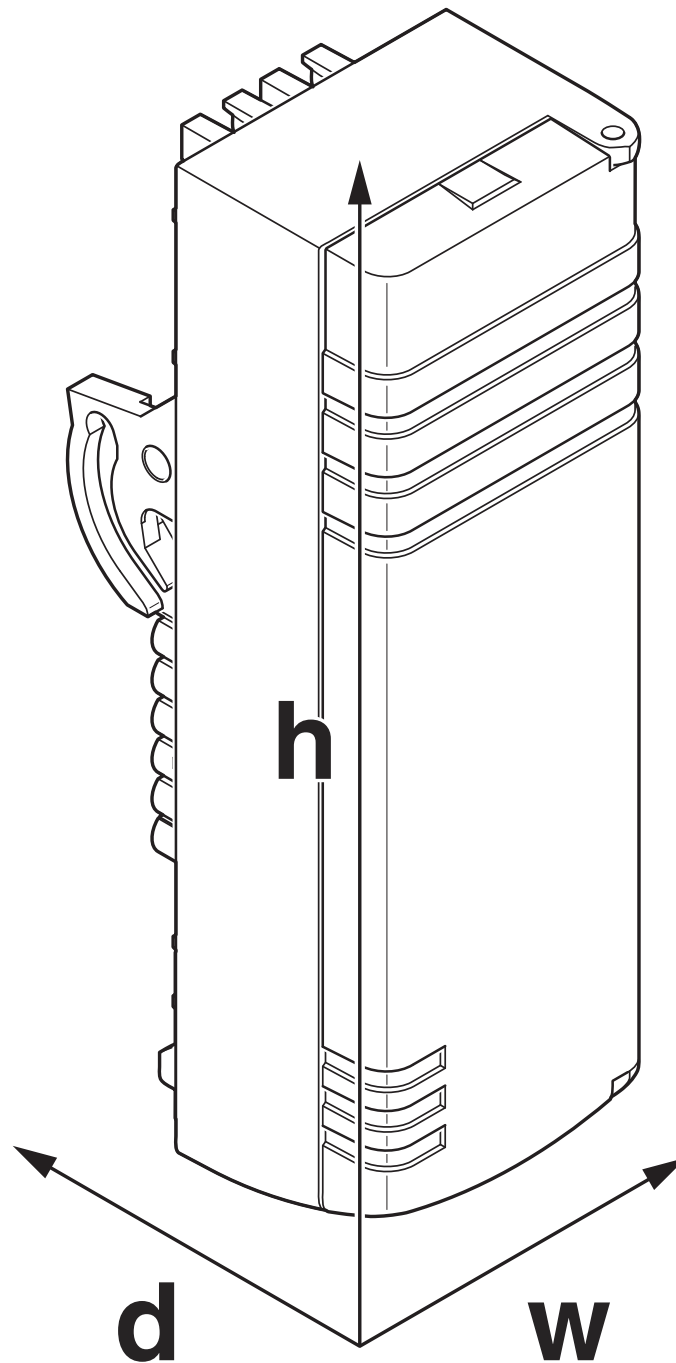


# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

## Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/2202053>



**UL Recognized**

Approval ID: E240868

# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27182702 |
| ECLASS-13.0 | 27190401 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC001031 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053  
<https://www.phoenixcontact.com/in/products/2202053>

## Environmental product compliance

|   |  |
|---|--|
| EU RoHS                                 |  |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |  |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|   | No hazardous substances above the limits |
| EU REACH SVHC                           |  |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

## Mandatory accessories

### ME PLC 40 B BUS 50/40 GY7035 - Mounting base housing

2201500

<https://www.phoenixcontact.com/in/products/2201500>



DIN rail housing, Lower housing part with metal foot catch, for 50/40 bus connector, width: 39.7 mm, height: 180.1 mm, depth: 137.7 mm, color: light gray (similar RAL 7035), cross connection: DIN rail connector (optional), number of positions cross connector: 50

---

### ME PLC 40 B BUS 10/10 GY7035 - Mounting base housing

2201499

<https://www.phoenixcontact.com/in/products/2201499>



DIN rail housing, Lower housing part with metal foot catch, for 10/10 bus connector, width: 39.7 mm, height: 180.1 mm, depth: 137.7 mm, color: light gray (similar RAL 7035), cross connection: DIN rail connector (optional), number of positions cross connector: 10



# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

## ME PLC 40 B BUS 50/40 YE - Mounting base housing

1001035

<https://www.phoenixcontact.com/in/products/1001035>



DIN rail housing, Lower housing part with metal foot catch, for 50/40 bus connector, width: 39.7 mm, height: 180.1 mm, depth: 137.7 mm, color: yellow (similar RAL 1018), cross connection: DIN rail connector (optional), number of positions cross connector: 50

---

## ME PLC 40 B BUS 50/40 BK - Mounting base housing

2202719

<https://www.phoenixcontact.com/in/products/2202719>



DIN rail housing, Lower housing part with metal foot catch, for 50/40 bus connector, width: 39.7 mm, height: 180.1 mm, depth: 137.7 mm, color: black (similar RAL 9005), cross connection: DIN rail connector (optional), number of positions cross connector: 50

---

## Accessories

# ME PLC 40 CT36 GY7035 VPE1 - Front connection module



2202053

<https://www.phoenixcontact.com/in/products/2202053>

## CRIMPFOX 6 - Crimping pliers

1212034

<https://www.phoenixcontact.com/in/products/1212034>



Crimping pliers, for ferrules without insulating collar according to DIN 46228 Part 1 and ferrules with insulating collar according to DIN 46228 Part 4, 0.25 mm<sup>2</sup> ... 6.0 mm<sup>2</sup>, lateral entry, trapezoidal crimp

---

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)