


FEATURES

- **Heat Stabilised Material:** Ensures performance in high-temperature environments up to 105°C
- **Nylon Construction:** Provides durability and strength for long-lasting use
- **UL 94 V-2 Fire Behaviour:** Offers a level of flame retardancy for added safety
- **Maximum Bundle Diameter of 35 mm:** Accommodates a wide range of cable sizes
- **Tensile Strength of 8 kg:** Ensures secure fastening and reduces the risk of breakage
- **Light Green Colour:** Allows for easy identification and organisation

RS PRO Heat Stabilised Cable Tie, 142mm Nylon

RS Stock No: 656-016

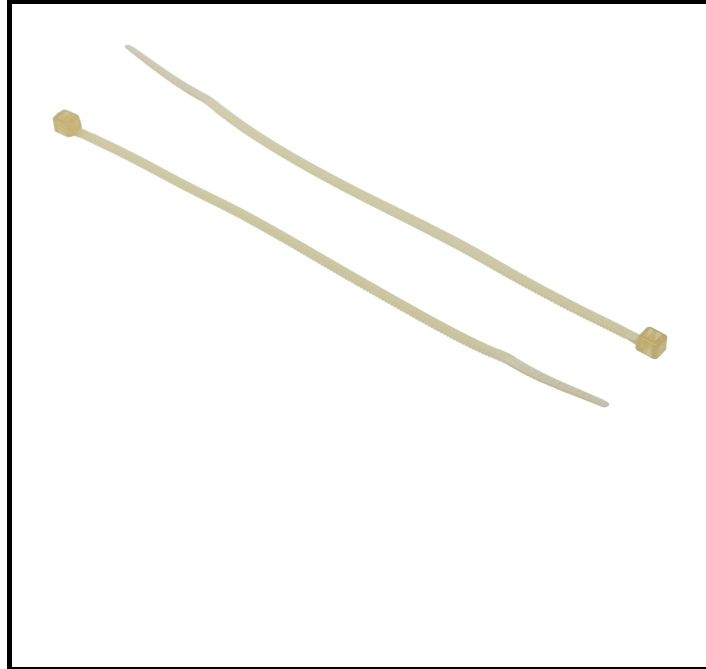

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

These RS PRO heat stabilised cable ties are designed for secure bundling and organising of cables and wires. Made from durable nylon, they are ideal for use in environments where heat resistance is crucial, offering reliable performance up to 105°C.

General Specifications

| | |
|------------------|-----------------|
| Colour | Light Green |
| Product Type | Cable Tie |
| Sub Type | Heat Stabilised |
| Tensile Strength | 8 kg |

Protection Category

| | |
|----------------|-----------|
| Fire Behaviour | UL 94 V-2 |
| UV Resistant | No |

Mechanical Specifications

| | |
|-------------------------|--------|
| Length | 142 mm |
| Material | Nylon |
| Maximum Bundle Diameter | 35 mm |
| Width | 2.5 mm |

Operation Environment Specifications

| | |
|-------------------------------|--------|
| Maximum Operating Temperature | 105 °C |
|-------------------------------|--------|

Approvals

| | |
|---------------------|---|
| Standards/Approvals | ABS 15-TA1338482-PDA, cULus E97527, RoHS, UL94V-2 |
|---------------------|---|

