

NT 70/3 ME TC

Save time and prevent back strain – the tilting chassis in the NT 70 range makes emptying the large containers simpler than ever: Operate the emptying point, lift the handle and say goodbye to dirt!



Order no. 1.667-274.0

- 70-l stainless steel container, three turbines, push handle, tilting chassis
- Powerful suction power with three turbines, drain hose, accessory storage
- 360 mm Adv floor nozzle, crevice nozzle, paper cartridge filter

Technical data

EAN code		4039784725423
Power supply	Ph / V / Hz	1 / 220 - 240 / 50 - 60
Air flow	l/s	3 × 74
Vacuum	mbar / kPa	254 / 25.4
Container capacity	l	70
Container material		Stainless steel
Rated input power	W	max. 3600
Standard nominal width		ID 40
Cable length	m	10
Sound pressure level	dB(A)	83
Colour		silver
Weight without accessories	kg	29.9
Weight incl. packaging	kg	35.8
Dimensions (L × W × H)	mm	510 × 645 × 990

Equipment

Suction hose length	m	4
Bend		Plastic
Quantity of suction tubes	Piece(s)	2
Suction tubes length	mm	550
Suction tubes material		Stainless steel
Tilting chassis		■
Wet/dry floor nozzle width	mm	360
Crevice nozzle		■
Cartridge filter		Paper
Drain hose		■
Stainless steel container		■
Push handle		■
Protection class		II
Stop swivel castor		■

■ included in the scope of supply.



Integrated accessory storage

- Large bumper with accessory storage.



Ergonomic push handle

- The NT 70 has an ergonomic push handle so that the machine can be pushed along.




Tilting chassis

- Quick and easy: the container tilts back for easy emptying.

ACCESSORIES FOR NT 70/3 ME TC

1.667-274.0

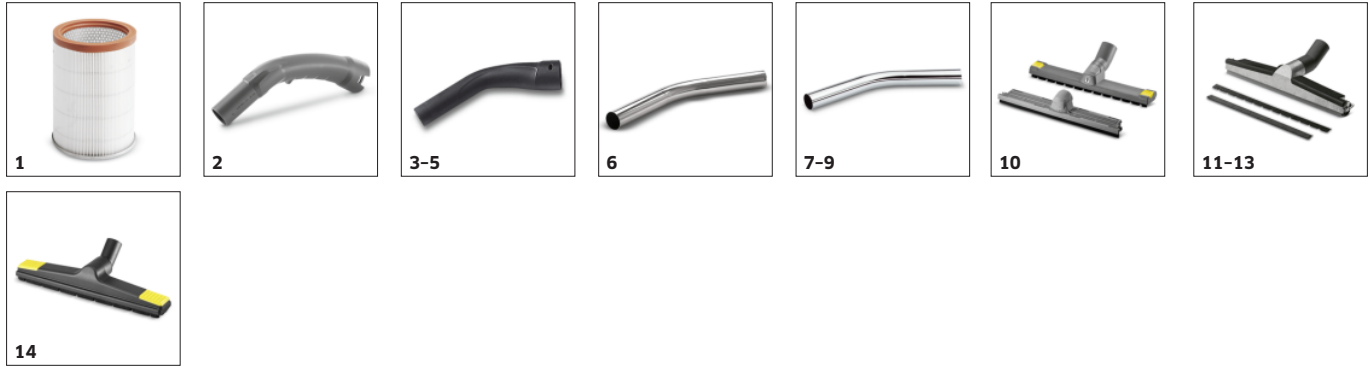

	Order no.	Description	
CARTRIDGE FILTER, STANDARD, UP TO BIA C, DUST CLASS M			
Cartridge filter paper			
Cartridge filter, paper	1 6.907-038.0	Paper cartridge filter (M BIA-C dust class M), suitable as a main filter for dry and wet pick up.	■
BENDS			
Bend, plastic			
Bend, NT, DN 40, plastic, clip 2.0 at hose end, cone at accessory end	2 2.889-171.0	DN 40 plastic bend for wet and dry vacuum cleaners. Equipped with a clip 2.0 connection at the hose end and a cone connection at the accessory end.	■
Bend, NT, DN 35, plastic, clip 1.0 at hose end, cone at accessory end	3 5.031-718.0	DN 35 plastic bend for wet and dry vacuum cleaners. Equipped with a clip 1.0 connection at the hose end and a cone connection at the accessory end.	□
Bend, NT, DN 35, plastic, electrically conductive, clip 1.0 at hose end, cone at accessory end	4 5.031-939.0	Electrically conductive DN 35 plastic bend for wet and dry vacuum cleaners. Equipped with a clip 1.0 connection at the hose end and a cone connection at the accessory end.	□
Bend, NT, DN 40, plastic, electrically conductive, clip 1.0 at hose end, cone at accessory end	5 5.032-427.0	Electrically conductive DN 40 plastic bend for wet and dry vacuum cleaners. Equipped with a clip 1.0 connection at the hose end and a cone connection at the accessory end.	□
Bend, other			
Bend, NT, DN 35, chrome-plated metal, cone at hose end, cone at accessory end	6 6.900-519.0	DN 35 chrome-plated metal bend for wet and dry vacuum cleaners by Kärcher. The bend has a cone connection at both the hose end and the accessory end.	□
Bend, NT, DN 35, stainless steel, cone at hose end, cone at accessory end	7 6.903-141.0	Robust DN 35 stainless steel bend for wet and dry vacuum cleaners by Kärcher. The bend has a cone connection at both the hose end and the accessory end.	□
Bend, NT, DN 40, chrome-plated metal, cone at hose end, cone at accessory end	8 6.900-276.0	DN 40 chrome-plated metal bend for wet and dry vacuum cleaners by Kärcher. The robust bend has a cone connection at both the hose end and the accessory end.	□
Bend, NT, DN 40, stainless steel, cone at hose end, cone at accessory end	9 6.902-079.0	Robust DN 40 stainless steel bend for wet and dry vacuum cleaners by Kärcher. The bend has a cone connection at both the hose end and the accessory end.	□
SUCTION NOZZLES			
Floor nozzles			
Wet/dry floor nozzle, Adv, DN 40, width 360 mm	10 2.889-153.0	Plastic Adv floor nozzle with width of 360 mm and nominal size of DN 40 for wet and dry vacuum cleaners from Kärcher. Features brush strips and squeegees that are easy to change.	■
Wet/dry floor nozzle, aluminium, DN 40, width 370 mm	11 6.903-018.0	Aluminium floor nozzle with rollers, width of 370 mm and nominal size of DN 40 for wet and dry vacuum cleaners from Kärcher. Includes easy-to-replace brush strips and squeegees.	□
Wet/dry floor nozzle, aluminium, DN 40, width 450 mm	12 6.906-383.0	Aluminium floor nozzle with rollers, width of 450 mm and nominal size of DN 40 for wet and dry vacuum cleaning. The brush strips and squeegees that are included are easy to change.	□
Wet/dry floor nozzle, aluminium, DN 35, width 370 mm	13 6.906-384.0	For wet and dry vacuum cleaners from Kärcher: aluminium floor nozzle (DN 35) with a width of 370 mm, including brush strips and squeegees that are easy to change.	□
Wet/dry floor nozzle, Adv, DN 40, width 400 mm	14 2.889-117.0	For wet and dry vacuum cleaners from Kärcher: plastic Adv floor nozzle with width of 400 mm and nominal size of DN 40. Includes easy-to-replace brush strips and squeegees.	□

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR NT 70/3 ME TC

1.667-274.0



		Order no.	Description	
SUCTION NOZZLES				
Crevice nozzles				
Crevice nozzle, NT, DN 40, plastic, 300 mm	15	5.130-655.0	Plastic crevice nozzle in nominal width DN 40 for Kärcher wet and dry vacuum cleaners. Especially suitable for vacuuming out areas that are difficult to reach, such as joints, crevices and corners.	■
Crevice nozzle, DN 35, plastic, length 210 mm	16	2.889-130.0	With the DN 35 plastic crevice nozzle, corners and crevices can be vacuumed quickly and thoroughly. Length: 210 mm.	□
Crevice nozzle, NT, DN 35, metal, 500 mm long	17	6.900-922.0	The metal crevice nozzle (DN 35) enables vacuuming in crevices and corners. Length: 500 mm.	□
Crevice nozzle, NT, DN 40, metal, 400 mm	18	6.905-817.0	Metal crevice tool (DN 40) for vacuuming in crevices and corners. Length: 400 mm.	□
All-purpose brushes				
All-purpose brush	19	6.903-863.0	Natural bristles (ox hair), bristle element 120 × 45 mm.	□
Car cleaning nozzles				
Car nozzle, ID 40, 90 mm	20	6.900-952.0	For retrofitting older Kärcher wet and dry vacuum cleaner models with bends in DN 40: Flat angled, convenient, plastic car cleaning nozzle with a working width of approx. 90 mm.	□
	21	2.840-095.0	Flat angled, convenient, plastic, DN 40 car cleaning nozzle specially designed for new Kärcher wet and dry vacuum cleaners with a clip system at the suction hose. Working width: Approx. 90 mm.	□
Wide nozzles				
Wide nozzle	22	4.130-432.0	Vacuuuming larger Areas in connection with NT 70/1, NT 70/2 or NT 70/3 versions only.	□
Rubber suction tools, nose 45°				
Rubber suction tool, nose 45°	23	6.902-104.0	45° rubber suction nozzle (DN 35), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	□
NT rubber suction nozzle, bevelled at 45°, DN 40	24	6.902-105.0	45° rubber suction nozzle (DN 40), oil-resistant and suitable for vacuuming machines. Only for NT vacuum cleaners.	□
Pipe dusting nozzles				
Pipe brush 35/100	25	6.903-035.0	Plastic, pipe diameter 100 mm	□
Pipe brush 35/200	26	6.903-036.0	Plastic, pipe diameter 200 mm	□
Suction brushes				
Suction brush	27	6.903-862.0	Rotatable suction brush (DN 35) with high-quality synthetic hair bristles. Dimensions of the brush attachment: 70 × 45 mm.	□
Suction brush, DN 32	28	6.903-887.0	The rotating suction brush (DN 32, plastic) with PA brush attachment measures 70 × 45 mm. Only for BV and T vacuum cleaners.	□

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR NT 70/3 ME TC

1.667-274.0



		Order no.	Description	
SUCTION TUBES				
Suction tubes, stainless steel				
Suction tube, 2 x, NT, DN 40, 550 mm long, stainless steel, suitable for: NT 50/1, NT 55/2, NT 65/2, NT 70/2, NT 70/3, NT 75/2	29	2.889-194.0	The suction tube set consists of 2 suction tubes made of high-quality stainless steel (DN 40 and 550 mm long each). For Kärcher wet and dry vacuum cleaners.	■
Suction tube, DN 35, 505 mm, stainless steel	30	6.902-154.0	Suction tube made of high-quality stainless steel in DN 35 and 505 mm long for wet and dry vacuum cleaners from Kärcher.	□
Suction tube, NT, DN 40, 550 mm long, stainless steel, suitable for: AP 100/50, NT 55/2, NT 65/2, NT 70/2, NT 70/3, NT 72/2, NT 75/2, NT 561, NT 611, NT 802 IV	31	6.902-081.0	Suction tube made of high-quality stainless steel in nominal width DN 40 and 550 mm long for wet and dry vacuum cleaners from Kärcher.	□
Suction tube, NT, DN 40, 1000 mm long, stainless steel, suitable for: NT 55/2, NT 65/2, NT 70/2, NT 70/3, NT 72/2, NT 75/2, NT 561, NT 611, NT 802 IV	32	6.906-531.0	The suction tube made of high-quality stainless steel (DN 40 and 1000 mm long) is suitable for wet and dry vacuum cleaners from Kärcher.	□
Suction tubes, metal				
Suction tube, NT, DN 35, 505 mm long, chrome-plated steel, suitable for: NT 25/1, NT 27/1, NT 30/1, NT 35/1, NT 40/1, NT 48/1, NT 50/1, NT 55/2, NT 65/2, NT 70/2, NT 70/3, NT 72/2, NT 75/1, NT 75/2, NT 611, NT 802 IV	33	6.900-514.0	The suction tube made of chrome-plated steel (DN 35, 505 mm long) is suitable for wet and dry vacuum cleaners from Kärcher.	□
SUCTION HOSES				
Suction hoses with clip system 2.0 (compatible with vacuum cleaners from model year 2017 on)				
Suction hose, NT, DN 40, length 4 m, clip 2.0, bayonet 2.0	34	2.889-138.0	The suction hose in nominal width DN 40 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	■
Suction hose, NT, DN 35, length 4 m, electrically conductive, clip 2.0, bayonet 2.0	35	2.889-137.0	The electrically conductive suction hose in nominal width DN 35 and with 4 m length is suitable for use with wet and dry vacuum cleaners from Kärcher.	□
Suction hose, NT, DN 40, length 2.5 m, clip 2.0, bayonet 2.0	36	2.889-139.0	The suction hose in nominal width DN 40 and with 2.5 m length is suitable for use with wet and dry vacuum cleaners from Kärcher.	□
Suction hose, NT, DN 40, length 4 m, oil-resistant, clip 2.0, bayonet 2.0	37	2.889-140.0	The oil-resistant suction hose in nominal width DN 40 and with 4 m length is suitable for use with wet and dry vacuum cleaners from Kärcher.	□
Suction hose, NT, DN 40, length 4 m, electrically conductive, clip 2.0, bayonet 2.0	38	2.889-141.0	The electrically conductive suction hose in nominal width DN 40 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	□
Suction hose, NT, DN 40, length 2.5 m, electrically conductive, clip 2.0, bayonet 2.0	39	2.889-142.0	The electrically conductive suction hose in nominal width DN 40 and with 2.5 m length is suitable for use with wet and dry vacuum cleaners.	□
Extension hose, NT, DN 40, length 2.5 m, clip 2.0, connecting adapter	40	2.889-146.0	The extension hose in nominal width DN 40 and with 2.5 m length is suitable for use with wet and dry vacuum cleaners from Kärcher.	□
Repair kit for suction hoses DN 40, Clip 2.0	41	2.889-150.0	Repair kit ID 40 for the new clip system.	□
Hose connection				
Adapter, ID 32/35, with internal thread	42	6.902-077.0	Electrically non-conductive adapter with internal thread. For connecting two suction hoses without connectors. Suitable for DN 32 or DN 35.	□

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR NT 70/3 ME TC

1.667-274.0



	Order no.	Description		
SUCTION HOSES				
Hose connection				
Connecting adapter, ID 40, with internal thread	43	6.900-286.0	Electrically non-conductive adapter with screw thread at both ends. For connecting 2 DN 40 suction hoses without connectors.	<input type="checkbox"/>
Suction hoses with clip system 1.0 (compatible with vacuum cleaners up to model year 2016)				
Repair kit for suction hoses DN 40 Clip 1.0	44	2.639-873.0	Repair set (C40) includes threaded hose adapters (without bayonet adapter) for industrial NT vacuum cleaners with clip system.	<input type="checkbox"/>
Extension hose, NT, DN 40, length 2.5 m, clip 1.0, connecting adapter	45	6.906-344.0	The extension hose in nominal width DN 40 and with 2.5 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose with bend, NT, DN 40, length 4 m, clip 1.0, bayonet 1.0	46	4.440-678.0	The suction hose with bend in nominal width DN 40 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose with DN_40 adapter, NT, DN 40, length 16 m, clip 1.0, bayonet 1.0	47	4.440-784.0	The suction hose with sleeve in nominal width DN 40 and with 16 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 10 m, clip 1.0, bayonet 1.0	48	6.906-279.0	The suction hose in nominal width DN 40 and with 10 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 4 m, clip 1.0, bayonet 1.0	49	6.906-321.0	The suction hose in nominal width DN 40 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 16 m, clip 1.0, bayonet 1.0	50	6.906-635.0	The suction hose in nominal width DN 40 and with 16 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 10 m, electrically conductive, clip 1.0, bayonet 1.0	51	6.906-877.0	The electrically conductive suction hose in nominal width DN 40 and with 10 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hoses with cone connection				
Suction hose, NT, DN 40, length 4 m, cone, bayonet 1.0	52	4.440-263.0	The suction hose in nominal width DN 40 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 4 m, oil-resistant, cone, bayonet 1.0	53	4.440-303.0	The oil-resistant suction hose in nominal width DN 40 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 10 m, cone, bayonet 1.0	54	4.440-463.0	The suction hose in nominal width DN 40 and with 10 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 10 m, electrically conductive, cone, bayonet 1.0	55	4.440-466.0	The electrically conductive suction hose in nominal width DN 40 and with 10 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 40, length 10 m, oil-resistant, cone, bayonet 1.0	56	4.440-612.0	The suction hose in nominal width DN 40 and with 10 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>

Available accessories.

ACCESSORIES FOR NT 70/3 ME TC

1.667-274.0



	Order no.	Description	
SUCTION HOSES			
Suction hoses with cone connection			
Suction hose, NT, DN 50, length 4 m, cone, bayonet 1.0	57 4.440-264.0	The suction hose in nominal width DN 50 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 50, length 3 m, cone, bayonet 1.0	58 4.440-328.0	The suction hose in nominal width DN 50 and with 3 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 50, length 10 m, cone, bayonet 1.0	59 4.440-467.0	The suction hose in nominal width DN 50 and with 10 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 50, length 4 m, oil-resistant, cone, bayonet 1.0	60 4.440-613.0	The oil-resistant suction hose in nominal width DN 50 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
Suction hose, NT, DN 50, length 4 m, electrically conductive, cone, bayonet 1.0	61 4.440-616.0	The electrically conductive suction hose in nominal width DN 50 and with 4 m length is suitable for use with wet and dry vacuum cleaners.	<input type="checkbox"/>
FILTER BAGS			
Fleece filter bags			
Fleece filter bags, 5 Piece(s), NT 65, NT 70, NT 72, NT 75, NT 90	62 2.885-753.0	Tear-resistant fleece filter bags of dust class M, suitable for Kärcher wet and dry vacuum cleaners. Contents: 5-pack.	<input type="checkbox"/>
Paper filter bags			
Paper filter bags, 5 Piece(s), NT 48, NT 65, NT 70, NT 72, NT 75, NT 80, WET VAC	63 6.904-285.0	Premium 3-layer paper filter bags of dust class M, suitable for Kärcher wet and dry vacuum cleaners. Contents: 5-pack.	<input type="checkbox"/>
FILTER T/ NT			
Coarse dirt filter for wet vacuuming			
Foam filter for wet applications of wet and dry vacuum cleaners NT 70, NT 72/2	64 2.889-083.0	Quick-drying foam filter for wet applications using wet and dry vacuum cleaners from Kärcher that have a mechanical floating switch off.	<input type="checkbox"/>
Wet filter bag			
Wet filter bag	65 6.904-252.0	Approved for dust class L, general cleaning, wet and dry, tear-resistant.	<input type="checkbox"/>
Plastic sacks for dust-free disposal			
Plastic bag for dust-free disposal, 10 Piece(s), NT 65, NT 70, NT 72, NT 75, NT 602, NT 700, NT 702	66 6.900-698.0	PE plastic sack.	<input type="checkbox"/>
Fabric filter			
Membrane filter, NT 65, NT 70, NT 72, NT 75, NT 551, NT 602, NT 700, NT 702, NT 802, NT 993	67 6.904-282.0	Polyester needle fleece membrane/fabric filter – BIA-C -, washable up to 40°C, metal fibres for earthing. Suitable for virtually all industrial two-motor NT vacuum cleaners.	<input type="checkbox"/>
CONNECTING SLEEVES			
Y-adapter kit			
Y-adapter kit	68 2.637-217.0	Plastic distributor – suitable for NT vacuum cleaners.	<input type="checkbox"/>
Connection adapter C ID (clip to cone)			
Adapter clip DN 35 on cone DN 35	69 5.407-005.0	Adapter clip system DN 35 for connecting suction tubes and small nozzles to cone DN 35. Perfect for vehicle interior cleaning, even without the connection of other nozzles.	<input type="checkbox"/>
Adapter clip DN 40 to cone DN 40	70 5.407-006.0	For connecting small nozzles and suction tubes with cone DN 40: Adapter clip system DN 40. Ideal for vehicle interior cleaning tasks, with no need to connect additional nozzles.	<input type="checkbox"/>

Available accessories.

ACCESSORIES FOR NT 70/3 ME TC


1.667-274.0



71-73



74

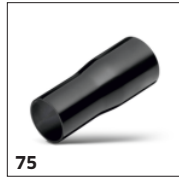

75



76



77



78



79



80

		Order no.	Description	
CONNECTING SLEEVES				
Connection adapter C ID (clip to cone)				
Connection adapter C DN 35	71	5.407-112.0	C 35 hose connector for DN 35 accessory, electrically conductive.	<input type="checkbox"/>
Electrically conductive DN 40 connection adapter for DN 35 accessories	72	5.407-109.0	Electrically conductive adapter (C 40) with DN 35 connection for connecting DN 35 accessories to an industrial C 40 or C-DN 40 suction hose. Suitable for NT vacuum cleaners.	<input type="checkbox"/>
Connection adapter C DN 40	73	5.407-111.0	C 40 hose connector for DN 40 accessory, electrically conductive.	<input type="checkbox"/>
Reducing sleeves				
NT reducer from DN 40 to DN 35, electrically conductive	74	5.407-108.0	Threaded reducer - from C-40 to DN 35. Suitable for NT vacuum cleaners.	<input type="checkbox"/>
Reducer adapter from DN 40 to DN 35	75	6.902-017.0	Reducer, enabling accessories (upholstery nozzle, crevice nozzle, etc.) with a DN 35 connection adapter to be connected to accessory parts (bend or suction tube) that have a DN 40 connection adapter.	<input type="checkbox"/>
NT reduction bushing with clip system for DN 40 suction hoses on accessory DN 35	76	5.407-113.0	Reducer (C 40 to C 35) for connecting accessories with C-35 clip connection to suction hoses with C 40 clip system.	<input type="checkbox"/>
Reducer from ID 35 to ID 32	77	6.902-072.0	Reducer with internal connecting cone DN 32. Ideal for accessories from the industrial vacuum cleaner range in combination with industrial NT vacuum cleaners.	<input type="checkbox"/>
OTHER ACCESSORIES NT				
Cyclone preseparator CS 40 Me	78	2.863-026.0	The highly efficient CS 40 Me cyclone preseparator for all Kärcher wet and dry vacuum cleaners is a specially designed accessory for fine dust applications on construction sites or in industry.	<input type="checkbox"/>
Adapter for NT hoses with bayonet connection 1.0	79	5.031-436.0	Electroconductive adapter for connecting NT hoses with bayonet 1.0 connection of nominal widths DN 35, 40, 50 to the new accessory system for wet and dry vacuum cleaners from Kärcher.	<input type="checkbox"/>
OTHER ACCESSORIES SCRUBBER DRIERS				
Miscellaneous				
Extension cable	80	6.647-022.0	Extension cable, 20 m, 3x1.5 mm ² . With splash-proof earthing pin plug, strain relief and anti-kink sleeve.	<input type="checkbox"/>

Available accessories.