



Duplo

- High output siren sound (126dB)
- Rugged construction for use in all environments
- Long life and run time
- Low voltage DC and high voltage AC for use in all applications
- Weatherproof to IP65
- Mounting bracket for ease of installation

The Duplo is a powerful motor driven siren producing a very high sound output from a small physical size.

With its weatherproof design, it can be used both indoors and outdoors for security, fire alarm, process control alarm and general safety warning.

Having a rugged construction, it can be used in arduous conditions including mining and quarrying applications and has a continuous rating and long life.


Applications

- General safety warning
- Conveyor alarm
- Fire and security alarm
- Process control alarm
- Crane alarm

Fire ✓
Security ✓

Industrial ✓
Railway/Marine X

Hazardous Area X
Public Warning X

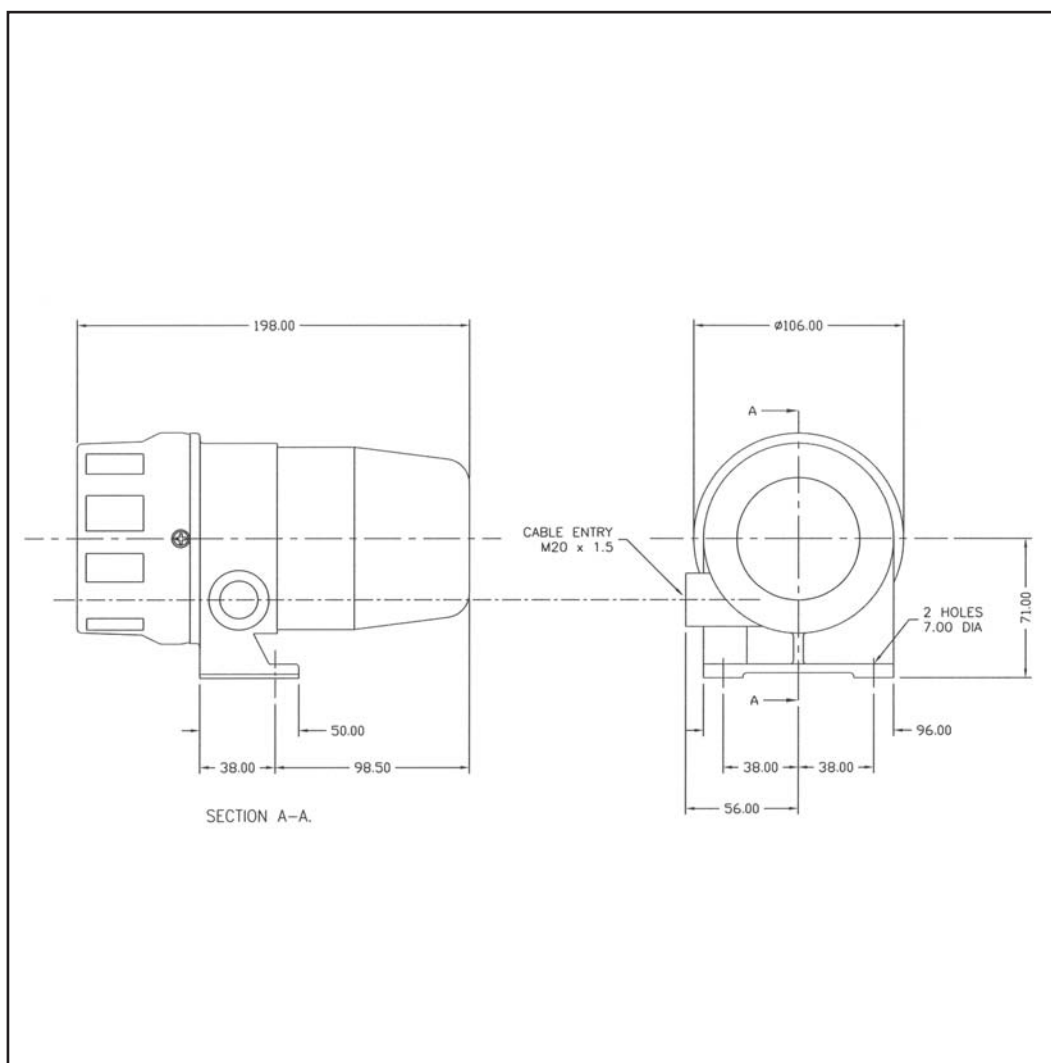

Part No.	Colours	Audibility at 1m	Tones	Voltage	Current
18-980211	Grey/Black	126dB (A) ±3dB	1	12V DC	15.0A
18-980212	Grey/Black	126dB (A) ±3dB	1	24V AC/DC	8.3A
18-980214	Grey/Black	126dB (A) ±3dB	1	110V AC/DC	2.0A
18-980217	Grey/Black	126dB (A) ±3dB	1	230V AC/DC	1.0A

IP Rating: IP65
Rating: On 15 minutes, off 10 minutes
Frequency: 1800Hz
Operating temp: -30°C to +45°C
Construction: Cast aluminium body, ABS rotor/stator/cover
Cable Entries: 1
Weight: 2kg