

Datasheet

Emergency Light Fitting Bulkhead Fluorescent

RS Stock number: 462-8208




Specifications:

Body:	Flame retardant polycarbonate
Diffuser:	Clear fresnel flame retardant polycarbonate
Charger LED:	Constant current with green LED for mains healthy and connected battery
Lamps:	8W T5 fluorescent or 11W TC-S compact fluorescent
LED's:	Mains versions 15 x 0.2W high lumen/Watt LED, emergency versions, 5 x 0.2W high lumen/Watt LED (125 lumens per Watt)

Lamp & Mode	Emergency Lumens	Weight
8 Watt NM3 bulkhead standard output	120	1.70kg

Dimensions

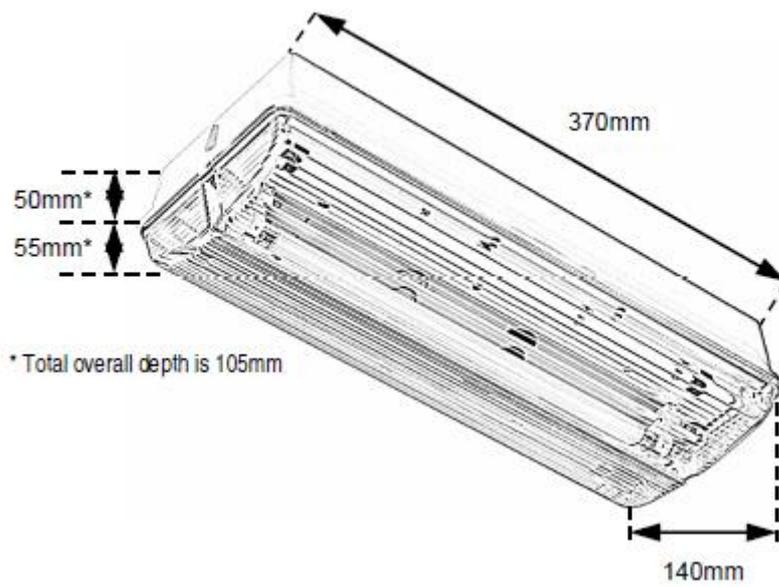

Installation Instructions:

- Connect the mains cable(s), which should be a maximum of 1mm² solid core.
- The supply for a non-maintained emergency circuit must be unswitched and is connected to the unswitched input.
- The supply to a non-emergency circuit can be switched and is connected to the switched input.
- If a single unswitched supply is used for both emergency and normal use a link should be connected between the unswitched supply and switched supply terminals.
- Mark the battery pack with date of installation and connect the battery to the module.
- For testing purposes a fused spur or keyswitch should be included in the unswitched supply.