
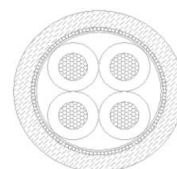


Datasheet

Stock No: 522-525

RS Pro 4 Core Screened CY Control Cable, Polyvinyl Chloride PVC Sheath

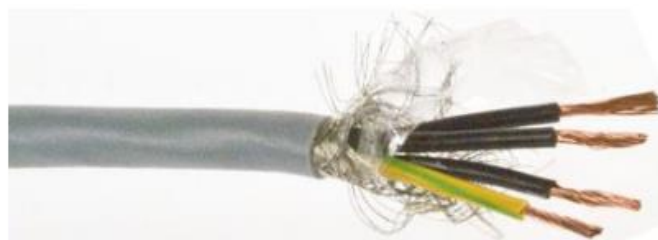

Construction:

Conductor: Bare Copper

Conductor Dia. (mm): $0.20 \pm 0.008 \times 32$

Insulation: PVC

Insulation Dia. (mm): $2.52 \pm 0.1 \times 4C$

Tape: Mylar

Braid Shield: Tinned Copper

Conductor Dia. (mm): 0.12

Conductor Qty: 16x8

Pitch(mm):

Coverage: 70%

Jacket: PVC

Outer Dia. (mm): 8.1 ± 0.25

Colour:

The colour of the insulation: Grey ,
Brown , Black ,
Yellow/Green

The jacket colour: Grey (RAL-7001)

Marking(3times/m):

RS 522525 CY/CC 4 Core x 1.0mm²

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):300

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<21.1

Min.Insulation DC Resistance at 20°C (MΩ*KM) :
>500

Current Rating : 10 A