




Data sheet

CSOT6

ENGLISH

RS Stock No. 407-1371

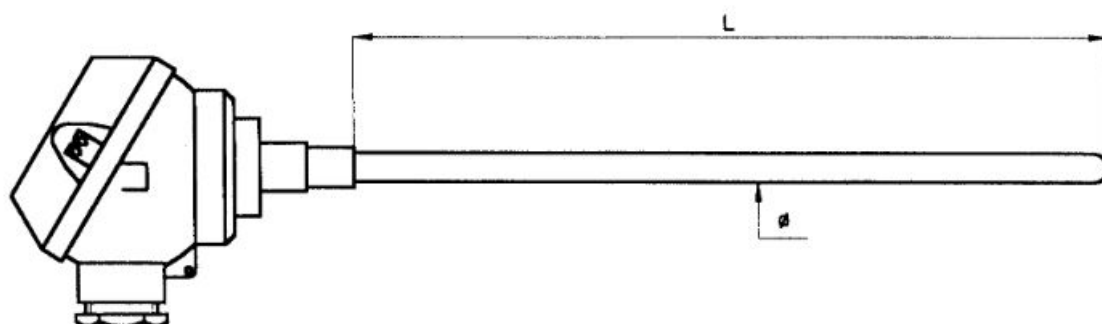

RTD WITH TRANSMITTER 4-20 mA

RANGE :

- -50 /250°C

USE :

- Universal

KEY POINT :

- Signal already converted in Machine language

SPECIFICATIONS :

- PT100Ω probe A Class – 1x3 wires assembly
- Tube Ø6 in 316L SS
- Head in Epoxy
- Out signal : 4-20 mA

DIMENSIONS :

- Sheath length = 300mm
- Thermic element diameter = 6mm

METROLOGICAL DATA :

- Class B :
As per IEC 751
Standard tolerance PT100 B class : $\pm 0.30 + 0.005 \cdot [t^{\circ}\text{C}]$