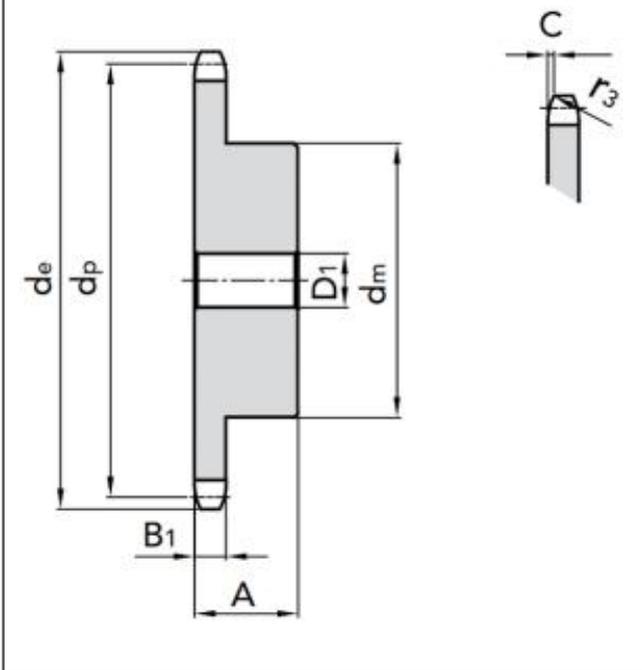
 


**10119015**

3/4in x 7/16in - Chain sprockets ISO

**2D Technical Drawing**

**Dynamic 3D View**

**Technical Specifications**

Number of teeth (T)	15
de (DE) mm	99.16
dp (DP) mm	91.63
Part number (CODE)	10119015
dm (DM) mm	70
D1 (D1) mm	14
A (A) mm	35
Tooth radius r3 (R3) mm	19
Radius width C (C) mm	2
Sprockets tooth width B1 (B1) mm	11.1
Weight (WEIGHT) kg	1.16
Material (MAT)	STEEL C 45