

# POWERSTREAM 10.8kW & 12kW instantaneous water heater



Powerstream used to supply hand wash basin and shower mixer

The highest rated single phase water heater in the UK market.  
An adaptable unvented instantaneous water heater with multi - directional mounting.

**New 12kW model, delivers 26% more flow rate than 9.5kW model and 66% more than a 7.2kW instant water heater.**

## User Features

- Water supplied up to three outlets.
- Water outlet via existing tap (especially suitable via spray tap).
- Plumbs directly into cold water mains.
- Multi directional mounting.
- Small compact unit.
- No standing heat losses.
- Fast response.
- Neon 'power on' indicator.
- 9.5kW / 10.8kW can be operated via a simple 45 amp pull cord switch.

## Flow Rate

The chart below shows the approximate water temperature which can be expected from Powerstream for different flow rates. The temperature of the mains supply can vary from 5°C in winter up to about 20°C in summer, with an average of about 12°C.


	4 lts/min	5 lts/min	6 lts/min
9.5kW	39/54 °C	32/47 °C	28/42 °C
10.8kW	44/58 °C	36/51 °C	31/46 °C
12.0kW	48/63 °C	39/54 °C	34/49 °C

## Recommended Accessories

In shower application, we only recommend the use of our shower mixer kit: Chrome and white mixer with white accessory kit and variable spray shower head.  
Catalogue Number: 85-793605

APPROVALS CCA

# CALIFORNIA 8.5kW performance & economy

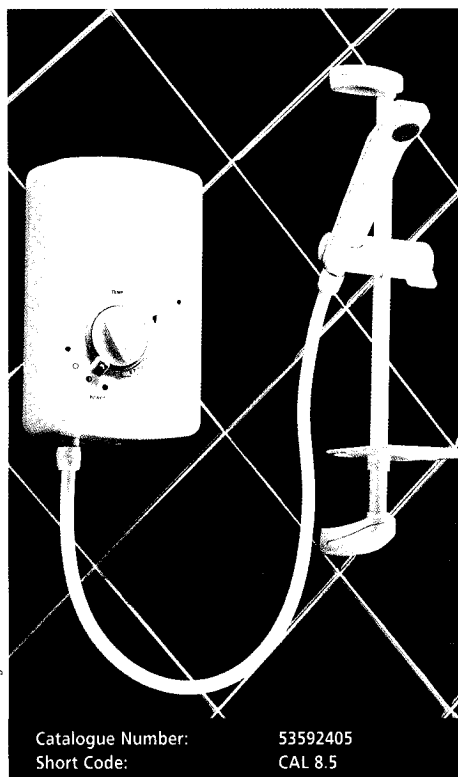

The new California 8.5 kW shower.

A new user friendly economy shower with deluxe performance.

## User Features

- Temperature / flow control with a single turn integral grip.
- Choice of 4 power settings (High / Med / Low / Cold).
- Separate controls for temperature control and power selection.
- Shallow backplate designed for ease of use.
- Safety high temperature cut-out.
- Detachable shower head.
- Single - mode handset.
- All polar white finish accessory kit as illustrated.
- Optional 5 year guarantee.

APPROVALS PENDING



kW Heat Settings	kW Loading @ 230 / 240V	Recommended Cable Size	Recommended Fuse Rating
0 / 3.7 / 4.8 / 8.5	8.5kW	6 / 10mm <sup>2</sup>	40 / 45 amps

Standard installer specifications: • Operating water pressure 0.7 - 7 Bar (10 - 100psi)  
• Water pressure operated power switch • Fixing pack included • Standard 15mm inlet connection  
• Top, bottom or rear water entry • Top, bottom or rear cable entry

# REDRING



GROUP OF COMPANIES

REDRING ELECTRIC LIMITED, MORLEY WAY, PETERBOROUGH PE2 9JJ TEL: 01733 313213 FAX: 01733 310606 Web Site: [www.redring.co.uk](http://www.redring.co.uk)  
Redring Electric Limited., (Northern Ireland) Unit 7 Westbank Road North Foreshore Belfast BT3 9LB Tel:01232 771400 Fax: 01232 777520

For further advice on our product range or for details of your local stockist / installer, please call 01733 313213

AS PART OF OUR CONTINUOUS DEVELOPMENT POLICY WE RESERVE THE RIGHT TO ALTER SPECIFICATIONS WITHOUT PRIOR NOTICE