

SERIES ANV - ISO "A" **QUICK RELEASE COUPLINGS**

MATERIALS

FEMALE	=	STEEL - WEAR PARTS CARBONITRIDED
MALE	=	HIGH GRADE CARBON STEEL - HARDENED
FINISH	=	ZINC/YELLOW PASSIVATED
VALVE	=	TEMPERED STEEL
SEALS	=	NITRIL (VITON/EPDM ON REQUEST)
RINGS	=	PTFE
TEMP. RANGE	=	-25°C TO +125°C




CONNECTION UNDER PRESSURE



MALE	NO
FEMALE	NO
BOTH	NO

DIMENSIONS

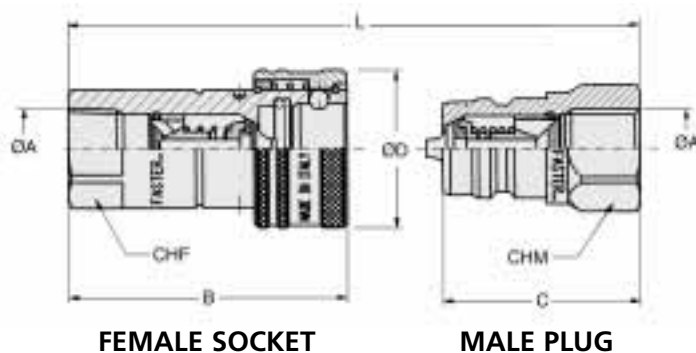

ØA	B	C	ØD	L	FS (CH)	MP (CH)
1/4"	47.2	38.6	25	71.3	19	19
3/8"	57	39	31	78	22	22
1/2"	66	44	38	88	27	27
3/4"	82.5	55	48	110	34	34
1"	100	66	56	132	41	41

FEMALE SOCKET

IDENT		84100	84101	84102	84103	84104
SIZE	BSP	1/4"	3/8"	1/2"	3/4"	1"
MAX PRESSURE	BAR	400	300	300	250	230
FLOW RATING	LPM	10	32	65	130	190

MALE PLUG

IDENT		84000	84001	84002	84003	84004
SIZE	BSP	1/4"	3/8"	1/2"	3/4"	1"
MAX PRESSURE	BAR	400	300	300	250	230
FLOW RATING	LPM	10	32	65	130	190

DUST CAP FOR FEMALE SOCKET

IDENT		TMA14	TMA38	TMA12	TMA34	TMA1

DUST CAP FOR MALE PLUG

IDENT		TFA14	TFA38	TFA12	TFA34	TFA1