

VALVE PLUG SUPPRESSOR FORM A - 18MM

Varistor and LED, 110VAC/DC/100VA/W

Art.No.: 3124046

Weight: 0.026

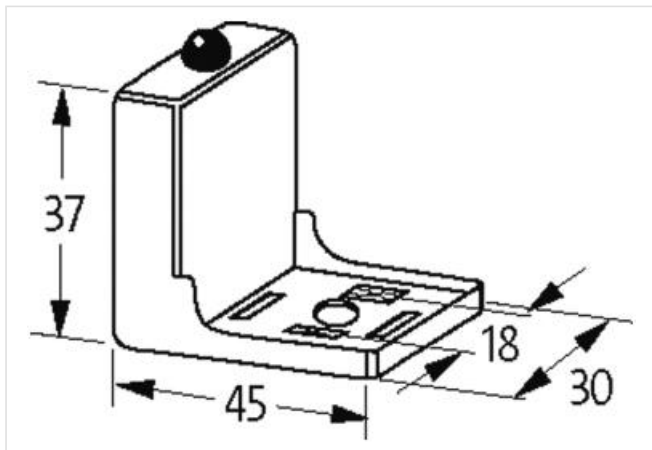
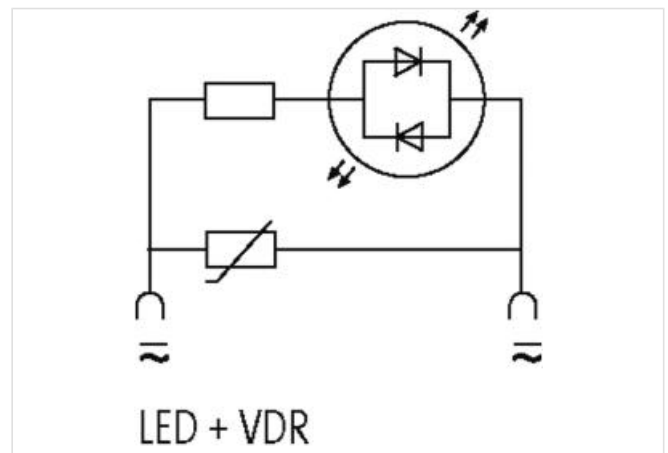
Country of origin: CZ

Model designation: VBS-LEDY+VDR 110 U

110 V AC/DC

VDR + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
customs tariff number	85363010
GTIN	4048879012225
Packaging unit	1

Electrical data

Drop-out delay time max.	10 ms
Holding power max.	100 W

Electrical data | Supply

Cut-off peak voltage max.	235 V
---------------------------	-------

Electrical data | Input

Input voltage AC min.	48 V
Input voltage AC max.	130 V
Input voltage DC min.	48 V
Input voltage DC max.	130 V

Diagnostics

Status indication LED	yellow
-----------------------	--------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Coating contact	silver-plated
Color housing	black
Material housing	PA
Material contact	Bronze

Mechanical data | Mounting data

Height	37 mm
Width	45 mm
Depth	30 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C