





TRIP ALARM SWITCH CHANGEOVER CONTACTS  
TYPE HP (14MM) ACCESSORY FOR 3VA-BREAKER



Model		
product brand name		SENTRON
General technical data		
Thermal current	A	10
Overvoltage category		III
Voltage		
Insulation voltage / Rated value	V	690
Surge voltage resistance / Rated value	kV	6
<b>Operating voltage</b>		
• at AC / at 50 Hz / Rated value / minimum	V	600
• at DC / Rated value / minimum	V	250
<b>Wire stripping length</b>	mm	15
Connectable conductor cross-section / maximum	mm <sup>2</sup>	2.5
Tightening torque / with screw-type terminals / maximum	N·m	0.5
<b>Height</b>	mm	56
<b>Width</b>		
• Note		2 slots (14 mm)

Depth	mm	30
Net weight	g	40
Degree of pollution		3

General Product Approval	EMC	Declaration of Conformity	Test Certificates
 CCC	 VDE		 EG-Konf.

[sonstig](#)

[Typprüfbescheinigung/Werkszeugnis](#)

other
<a href="#">sonstig</a>

### Further information

**Information- and Downloadcenter (Catalogs, Brochures,...)**

<http://www.siemens.com/lowvoltage/catalogs>

**Industry Mall (Online ordering system)**

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/3VA99880AB11>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<http://support.automation.siemens.com/WW/view/en/3VA99880AB11/all>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3VA99880AB11](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA99880AB11)

**CAX-Online-Generator**


<http://www.siemens.com/cax>

**Tender specifications**

<http://ausschreibungstexte.siemens.com/tiplv>

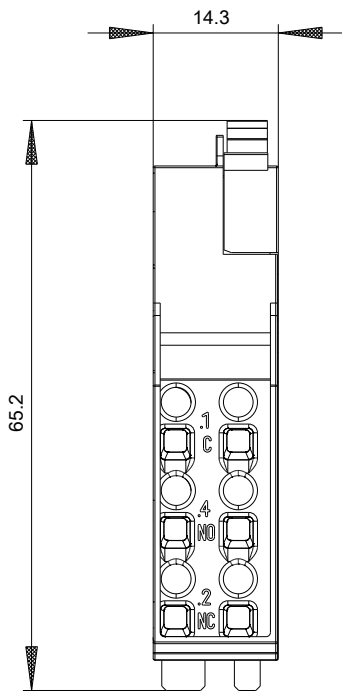

last modified:

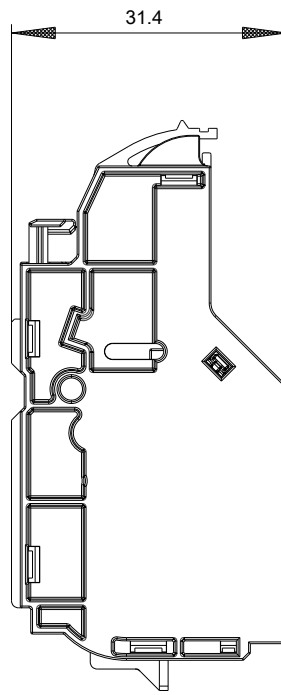

20.07.2015