



PRODUCT DATASHEET

Datasheet creation date: 2025/05/28 10:35 (UTC)

MOTION & CONTROL
NSK



22332CAME4

Spherical Roller Bearings

Parts Number

22332CAME4C4

Boundary Dimensions


d	160	mm	Bore diameter
D	340	mm	Outside diameter
B	114	mm	Width
r (min.)	4	mm	Chamfer dimension

Basic Load Ratings

Cr	1700000	N	Basic dynamic load rating
C0r	1900000	N	Basic static load rating


Speeds

Thermal Speed Rating (Oil-bath)	1400	min-1	Oil-bath lubrication subject to conditions outlined in ISO 15312
Mechanical (forced-circulation oil)	2200	min-1	Properly designed and controlled forced-circulation oil lubrication
Grease	1100	min-1	Grease lubrication
Oil (Oil-bath)	1300	min-1	Oil-bath lubrication

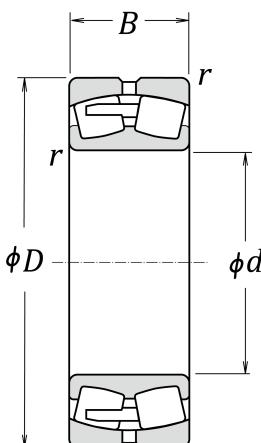

Abutment and Fillet Dimensions

da (min.)	178	mm	Diameter of shaft abutment
Da (min.)	287	mm	Diameter of housing abutment
Da (max.)	322	mm	Diameter of housing abutment
ra (max.)	3	mm	Radius of shaft or housing fillet

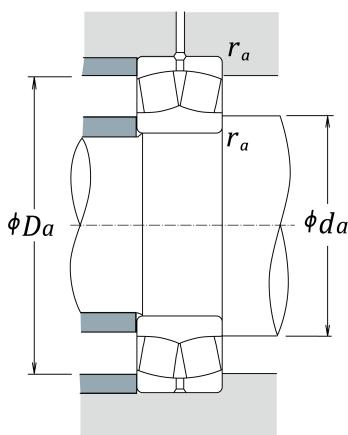

Calculation factors

e	0.35	Constant
Y2	2.9	Axial load Factors
Y3	1.9	Axial load Factors
Y0	1.9	Axial load Factors

Mass

Mass approx.	49.4	kg	Mass approx.
--------------	------	----	--------------