
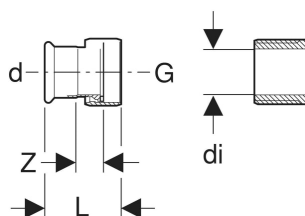


Geberit Mapress Copper adaptor with union nut

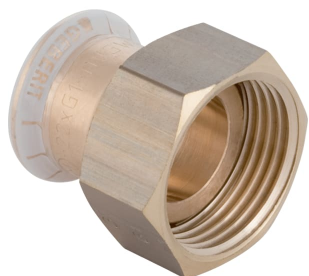

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water $\leq 120\text{ }^{\circ}\text{C}$
- For service water and process water
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)

- Suitable exclusively for threads with an inner diameter of $\leq d_i$, see table
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed up to $\varnothing \leq 54\text{ mm}$
- Union nut made of brass
- Seal ring made of CIIR, black, up to $\varnothing \leq 54\text{ mm}$

- Seal ring made of EPDM, black, from $\varnothing > 54\text{ mm}$
- Flat gasket made of EPDM
- Pressing socket with transparent protection plug

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	Gunmetal / lead-free gunmetal

Art. no.	DN	$d, \varnothing$ mm	G "	Product material	$d_i, \varnothing$ mm	L cm	Z cm
65081	10	12	1/2	Gunmetal	10	3.2	0.9
65182	12	15	1/2	Lead-free gunmetal	10	5.1	2.5
65082	12	15	3/4	Lead-free gunmetal	13	3.7	1.1
65083	15	18	3/4	Lead-free gunmetal	13	3.7	1.1

<i>Art. no.</i>	<i>DN</i>	<i>d, ø mm</i>	<i>G "</i>	<i>Product material</i>	<i>d_i, ø mm</i>	<i>L cm</i>	<i>z cm</i>
65040	15	18	1	Lead-free gunmetal	20	3.9	1.3
65084	20	22	1	Gunmetal	20	4	1.1
65044	20	22	1 1/4	Lead-free gunmetal	26	4.3	1.3
65045	20	22	1 1/2	Lead-free gunmetal	32	4.4	1.3
65046	25	28	1	Lead-free gunmetal	20	5.5	1.3
65085	25	28	1 1/4	Lead-free gunmetal	26	4.4	1.3
65050	25	28	1 1/2	Lead-free gunmetal	32	4.6	1.3
65086	32	35	1 1/2	Lead-free gunmetal	32	4.8	1.3
65051	32	35	2	Lead-free gunmetal	42	4.8	1.2
65087	40	42	1 3/4	Lead-free gunmetal	39	5.2	1.3
65052	40	42	2	Lead-free gunmetal	42	5.4	1.4
65053	40	42	2 1/4	Lead-free gunmetal	42	5.6	1.4
65088	50	54	2 3/8	Gunmetal	51	5.8	1.5

Art. no.	DN	d, ø mm	G "	Product material	d _i , ø mm	L cm	Z cm
65054	50	54	2 1/2	Lead-free gunmetal	54	6.3	1.4
65090	65	76.1	3	Gunmetal	73	9.1	2.5
65091	80	88.9	3 1/2	Gunmetal	84	9.8	2.4