

64193CBI

COOL BLUE INTENSE | Halogen headlight lamps for cars



Areas of application

- Headlight
- Ideal for use in clear-glass headlights

Product benefits

- Stylish look
- Up to 20 % more light (compared to standard halogen lamps)
- Bluish white light for xenon look

Product features

- Color temperature: up to 4,200 K
- High luminous flux
- Headlight lamp for bluest legally approved halogen light
- Modern design with a silver cap (H4/H7)

Product datasheet

Technical data

Electrical data


Power input	75 / 68 W ¹⁾
Nominal wattage	60.00 W
Nominal voltage	12 V
Test voltage	13.2 V

¹⁾ Maximum

Photometrical data

Color temperature	4100 K
Luminous flux	1650/1000 lm
Luminous flux tolerance	±12 / ±15 %

Dimensions & weight

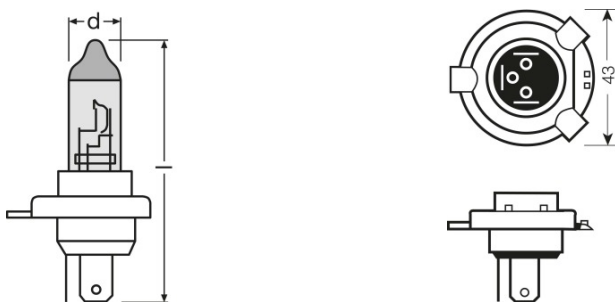

Product line drawing

Base

Length	82.0 mm
Diameter	17.0 mm
Product weight	25.60 g

Lifespan

Lifespan B3	50 / 200 h ¹⁾
Lifespan Tc	100 / 400 h ¹⁾

¹⁾ Filament 1 / Filament 2

Additional product data

Base (standard designation)	P43t
-----------------------------	------

Product datasheet

Certificates & standards

ECE category	H4
--------------	----

Country specific categorizations

Order reference	64193CBI 60/55W
-----------------	-----------------

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321650733	64193CBI	Hard Cover Box 2	95 mm x 47 mm x 115 mm	0.51 dm ³	135.20 g
4008321650740	64193CBI	Shipping carton box 20	240 mm x 106 mm x 250 mm	6.36 dm ³	1430.00 g
4008321650894	64193CBI	Folding carton box 1	47 mm x 47 mm x 71 mm	0.16 dm ³	28.00 g
4008321650900	64193CBI	Bundle 10	240 mm x 71 mm x 94 mm	1.60 dm ³	284.00 g
4008321650917	64193CBI	Shipping carton box 100	250 mm x 160 mm x 485 mm	19.40 dm ³	3127.00 g
4008321651280	64193CBI	Blister 1	53 mm x 51 mm x 93 mm	0.25 dm ³	32.00 g
4008321651297	64193CBI	Shipping carton box 10	116 mm x 145 mm x 335 mm	5.63 dm ³	466.00 g
4008321651303	64193CBI	Blister 2	87 mm x 51 mm x 111 mm	0.49 dm ³	57.00 g
4008321651310	64193CBI	Shipping carton box 20	146 mm x 146 mm x 475 mm	10.13 dm ³	766.00 g
4008321651327	64193CBI	Unpacked 1	- x - x -		
4008321651334	64193CBI	Shipping carton box 200	345 mm x 315 mm x 485 mm	52.71 dm ³	6562.00 g
4008321660343	64193CBI	Hard Cover Box 2	- x - x -		
4008321660350	64193CBI	Shipping carton box 20	106 mm x 240 mm x 250 mm	6.36 dm ³	1492.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.