


Flat cable
KASI-1,5-Y-100
Part number: 18940

FESTO

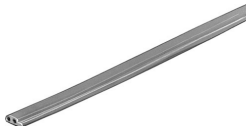

 [General operating condition](#)

Data sheet

Feature	Value
Product weight	71 g
Operational voltage range DC	≤75 V
Operational voltage range AC	≤60 V
Permissible current load	3 A
Cable length	100 m
Degree of protection	IP65 With sealed wire ends
Ambient temperature	-40 °C ... 85 °C
Ambient temperature with moving cable	-25 °C ... 85 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Material cable sheath	Rubber compound
Cable sheath colour	Yellow