


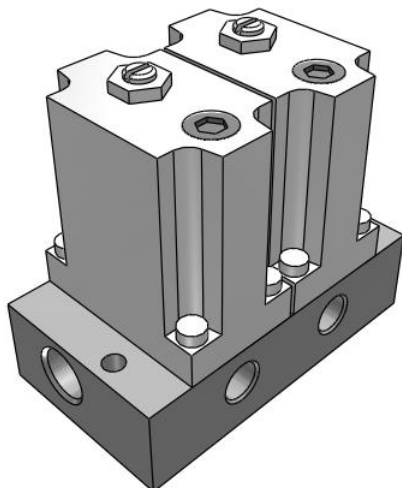


ARM1000/2000, Regulator Manifold Series

ARM2000-2A1-01

Datasheet

General series information






 
- Regulator manifold series, metric
- Small size pressure gauge ø15
- 4 connection methods
- Maximum operating pressure: 0.8MPa



Standard specifications

Size	2 (Size 2000 Flow 240NI/min)
Stations	2 Stations
Piping Specification	A1 (IN: Common OUT: Manifold)
Thread	Rc(PT)
Accessory	w/o Accessory
Option	None
Maximum temperature of pressure medium	60 °C
Minimum temperature of pressure medium	-5 °C (with no freezing)
Maximum operating pressure	0.8 MPa
Proof pressure	1.2 MPa
Set pressure range	0.05 - 0.7 MPa
Applicable fluid	Air
Relief mechanism	Relieving type
Weight	0.419 Kg

Dimensions

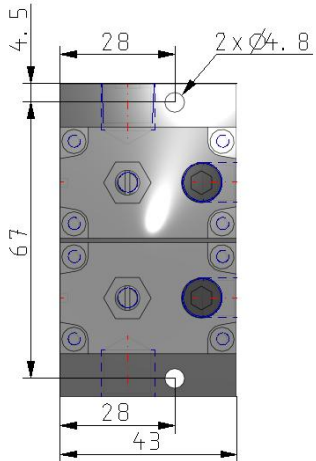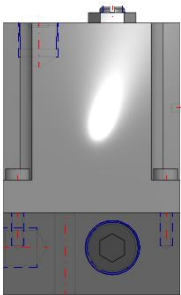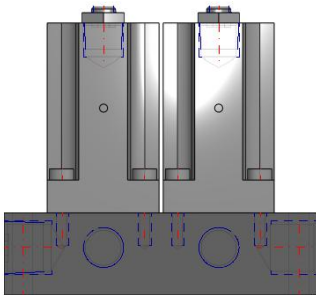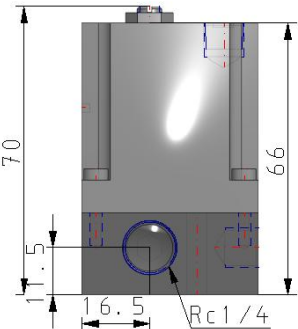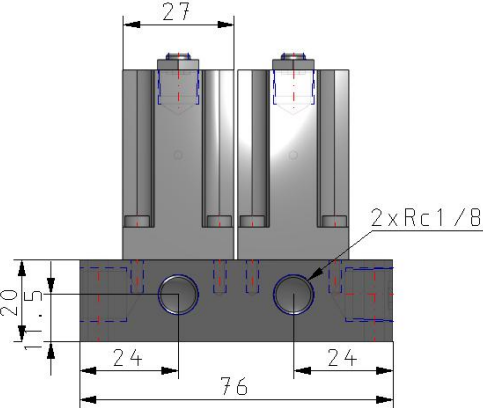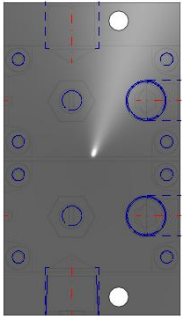

Additional information

Catalogue

[ARM_EU.pdf](#)