


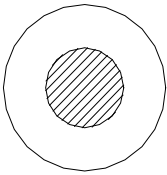

Product Name:	UL1180 28AWG
Product Discription:	UL1180 28AWG
Specification No.:	
Customer's Name:	

Description				
Rated Voltage:	300Vac(UL allows 600V for electronic use only).			
Rated Temperature:	200℃,Optional - 80 ℃ Oil, Gasoline Resistant.			
Reference Standard:	UL758			
Cross Section				
				
Marking				
No marking on the cable jacket, have UL label on the Reel.				
Applications				
For internal wiring of electronic and electrical equipment				
Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Danniel	Jason	24/04/2015
Construction				
Conductor	Stranded Sliver plated copper			
Size(AWG)	28			
Construction(±0.008mm)	7/0.127			
Stranded Dia.(mm)Ref.	0.38			
Insulation Material	PTFE			
Insulation Color	ANY COLOR			
Ave Thickness(mm)	0.33			
Insulation Dia.(±0.08mm)	1.14			
Remark:				
8740135 Red 8740144 Blue 8740157 Grey 8740166 Violet 8740138 Black 8740147 White 8740150 Yellow 8740131 Brown 8740141 Green 8740153 Orange				
Characteristics				Customer Approve
Test Item		Standard Value		Seal & Stamp
Test Material		PTFE(ROHS)		
Insulation resistance(20℃ MΩ*m		1000		
Vol. Tesr(AC.V.60S) (V)		2000		
Flammability Test		Horizontal flame		
Max.DC Resistance(20℃ Ω/km)		203(MAX)		
				Signature:
				Date: