


Model No.DFT129F CORDLESS SCREWDRIVER

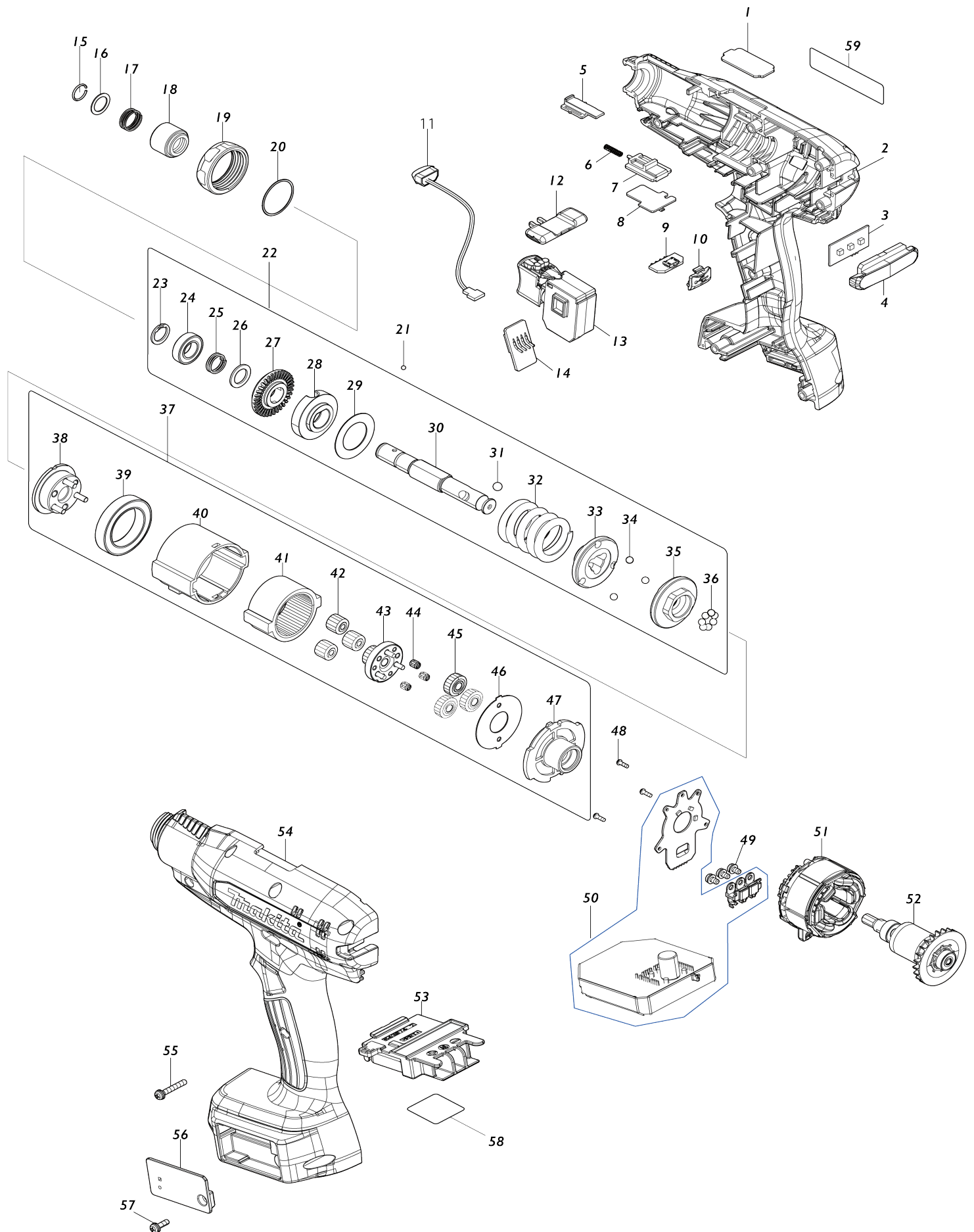

Model No.DFT129F CORDLESS SCREWDRIVER

Item No.	Parts No.	Description	Interchangability	Q'ty	New/Old	Note1	Note2
001	345345-2	PLATE I		1			
002	183W31-3	HOUSING SET		1	*		
C10	263005-3	RUBBER PIN 6		2	*		
C20	931002-4	HEX. NUT M3		8	*		
002		INC. 54			*		
002-1	1830L9-2	HOUSING SET	S	1			
C10	263005-3	RUBBER PIN 6		2			
C20	931002-4	HEX. NUT M3		8			
002-1		INC. 54					
003	620622-6	LED CIRCUIT		1			
004	457484-7	LENS		1			
005	412712-7	CHANGE PLATE		1			
006	233025-1	COMPRESSION SPRING 2		1			
007A	140U90-8	SWITCH LEVER COMPLETE		1	*		
007-1 A	141N44-6	SWITCH LEVER COMPLETE	<	1	*		
007-1 B	141N44-6	SWITCH LEVER COMPLETE		1	*		
007-2	141Y37-9	SWITCH LEVER COMPLETE	S	1			
008	620D61-4	SENSOR CIRCUIT		1			
009	620J83-0	USB CIRCUIT		1			
010	144709-5	USB COVER COMPLETE		1			
011	620J82-2	LED CIRCUIT		1			
012	457469-3	F/R CHANGE LEVER		1			
013	651082-1	SWITCH C3JW-1B-S		1			
014	620621-8	BUZZER CIRCUIT		1			
015	233930-2	RING SPRING 9		1			
016	267070-4	FLAT WASHER 10		1			
017	232374-3	COMPRESSION SPRING 10A		1			
018	161607-8	BIT SLEEVE		1			
019	457530-6	LOCK NUT M28 BLACK		1			
020	213836-0	O-RING 22		1			
021	216015-9	STEEL BALL 2.4		2			
022	122C84-7	CLUTCH ASSEMBLY 12MR		1	*		
022		INC. 23-36			*		
022-1	122H25-3	Clutch assembly 12MR	<	1			
022-1		INC. 23-36					
023	961026-6	RETAINING RING S-10		1			
024	210076-1	BALL BEARING 6800LLB		1			
025A	232375-1	COMPRESSION SPRING 10B		1	*		
025-1 A	232656-3	COMPRESSION SPRING 11	O	1			
025-1 B	232656-3	COMPRESSION SPRING 11		1			
026	267047-9	FLAT WASHER 10		1			
027	324834-0	LOCK NUT M12		1			
028	158408-3	ADJUST RING COMPLETE		1			
029	267276-4	FLAT WASHER 18		1			
030	327A31-3	SPINDLE MR		1			

031	216018-3	STEEL BALL 5.0		3			
032	233358-4	COMPRESSION SPRING 19C		1			
033	223146-7	CAM D		1	*		
033-1	223202-3	Cam G	S	1			
034	216024-8	STEEL BALL 4		3			
035	223187-3	CAM F		1	*		
035-1	223203-1	Cam H	S	1	*		
035-2	223206-5	Cam I	O	1			
036	216024-8	STEEL BALL 4		7			
037	136815-0	GEAR ASSEMBLY		1	*		
037		INC. 38-47			*		
037-1	137124-0	GEAR ASSEMBLY	<	1	*		
037-1		INC. 38-47			*		
037-2	137205-0	GEAR ASSEMBLY	<	1	*		
037-2		INC. 38-47			*		
037-3	1915J9-4	Gear assembly Q	O	1			
037-3		INC. 38-47					
038	144382-1	CARRIER COMPLETE C		1	*		
038-1	1410C8-7	Carrier complete C	<	1			
039	211375-4	BALL BEARING 6805LLB		1			
040	413J94-0	GEAR CASE		1	*		
040-1	4130Y3-4	GEAR CASE	S	1			
041	227048-9	INTERNAL GEAR 47		1			
042	221539-2	SPUR GEAR 14		3			
043	144933-0	SPUR GEAR 17 COMPLETE B		1			
044	212194-1	NEEDLE CAGE 205		3			
045	221540-7	SPUR GEAR 19		3			
046	267774-8	LOCK WASHER		1			
047	418003-4	MOTOR BRACKET		1			
048	266490-9	TAPPING SCREW PT 2X6		3			
049	652069-6	FLAT HEAD SCREW M3X6		3			
050A	620J81-4	CONTROLLER		1			
050B	620N37-1	Controller		1			
051	629B33-4	STATOR		1			
052	619443-1	ROTOR		1			
053	643874-2	TERMINAL		1			
054	183W31-3	HOUSING SET		1	*		
C10	263005-3	RUBBER PIN 6		2	*		
C20	931002-4	HEX. NUT M3		8	*		
054		INC. 2			*		
054-1	1830L9-2	HOUSING SET	S	1			
C10	263005-3	RUBBER PIN 6		2			
C20	931002-4	HEX. NUT M3		8			
054-1		INC. 2					
055	251581-9	PAN HEAD SCREW M3X20		8			
056	412358-9	COVER		1			
057	911013-5	PAN HEAD SCREW M3X10		1			
058	858T48-4	DFT129F SERIAL NO. LABEL		1			
059	858T43-4	DFT129F NAME PLATE		1			

Please state Parts No. when your order.

Print Date 06/09/2025