

SELOS WTPN · 2.5 mm² KNIFE DISCONNECT TERMINAL

WTPN 2.5 TKM

- Push-in connection / mounting on DIN rail TH35
- Nominal cross section 2.5 mm²
- Screwdriver 0.6x3.5



Description	Type	Part No.	Std. Pack
Knife Disconnect Terminal	grey WTPN 2.5 TKM	5D.203.2055.0	

GENERAL DATA

Width / length / height, incl. TS 7.5	5.1 mm / 61.7 mm / 36.6 mm
Wire strip length	10 mm

TECHNICAL DATA	IEC	UL 1059 / CSA 158
----------------	-----	-------------------


Cross section fine-stranded	0.14 - 2.5 mm ²	
Cross section solid/stranded	0.14 - 4 mm ²	
Cross section, AWG (sol/str)		22-10
Rated current	20 A	16 A
Rated voltage	400 V	300 V
Rated impulse voltage	6 kV	
Pollution degree	3	

ACCESSORIES	Type	Part No.	Std. Pack
End Plate	grey APWTPN 2.5 TK...	0D.203.1955.0	



WTPN 2.5 E TKM

- Push-in connection / mounting on DIN rail TH35
- Nominal cross section 2.5 mm²
- Screwdriver 0.6x3.5

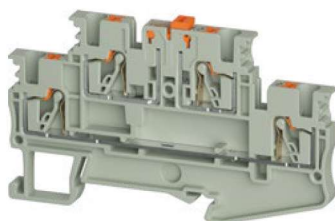

Description	Type	Part No.	Std. Pack
Knife Disconnect Terminal	grey WTPN 2.5 E TKM	5D.203.2255.0	

GENERAL DATA

Width / length / height, incl. TS 7.5	5.1 mm / 78.5 mm / 47.6 mm
Wire strip length	10 mm

TECHNICAL DATA	IEC	UL 1059 / CSA 158
----------------	-----	-------------------

Cross section fine-stranded	0.14 - 2.5 mm ²	
Cross section solid/stranded	0.14 - 4 mm ²	
Cross section, AWG (sol/str)		26-12
Rated current	20 A	Upper : 18 A / Lower : 20 A
Rated voltage	400 V	300 V
Rated impulse voltage	6 kV	
Pollution degree	3	

ACCESSORIES	Type	Part No.	Std. Pack
End Plate	grey APWTPN 2.5 E TKM	0D.203.3055.0	

