
 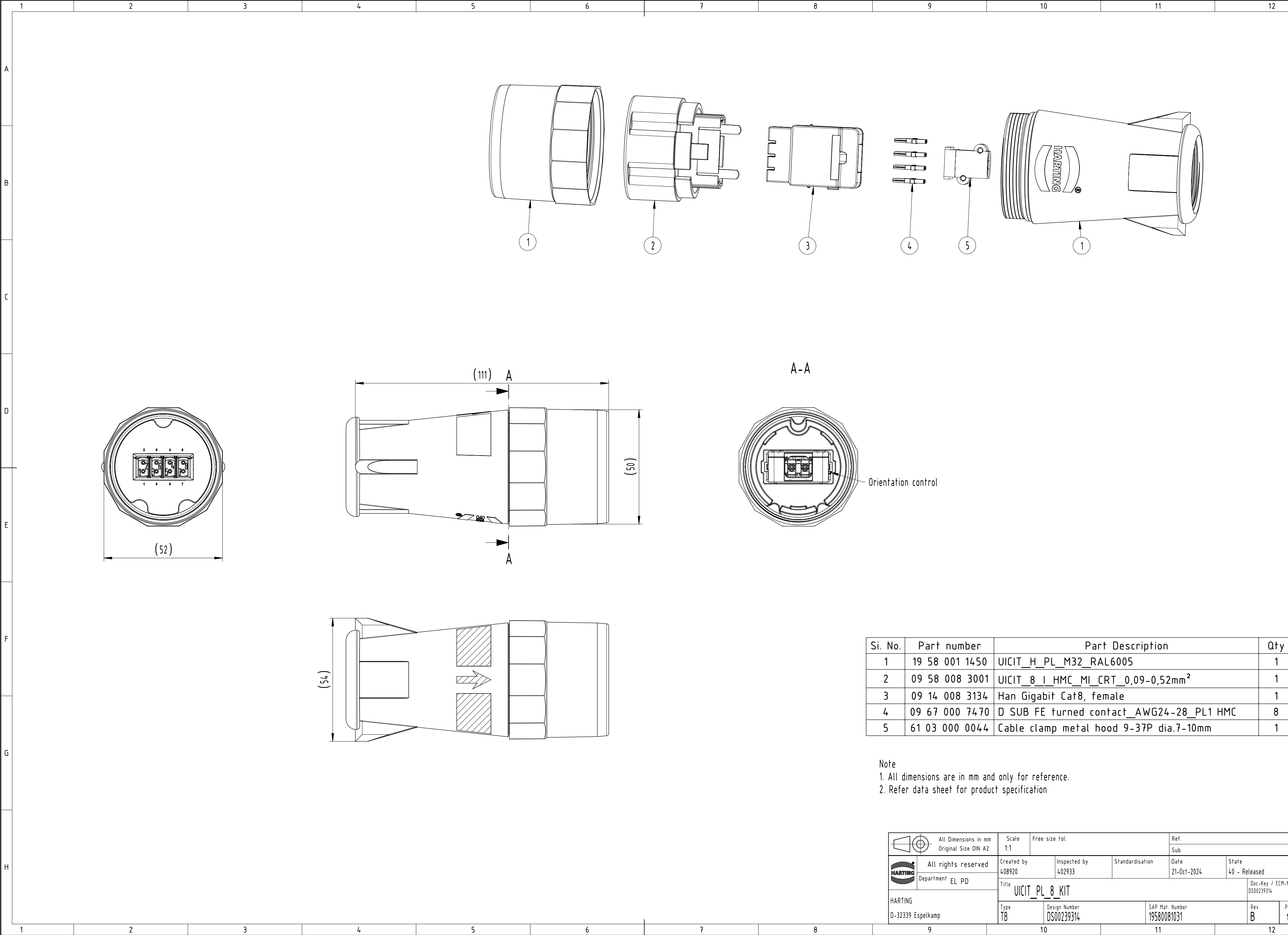
 




Si. No.	Part number	Part Description	Qty
1	19 58 001 1450	UICIT_H_PL_M32_RAL6005	1
2	09 58 008 3001	UICIT_8_I_HMC_MI_CRT_0,09-0,52mm ²	1
3	09 14 008 3134	Han Gigabit Cat8, female	1
4	09 67 000 7470	D SUB FE turned contact_AWG24-28_PL1 HMC	8
5	61 03 000 0044	Cable clamp metal hood 9-37P dia.7-10mm	1

Note
1. All dimensions are in mm and only for reference.
2. Refer data sheet for product specification

		All Dimensions in mm Original Size DIN A2		Scale 1:1	Free size tol.		Ref.		
		All rights reserved		Created by 408920	Inspected by 402933	Standardisation	Date 21-Oct-2024	State 40 - Released	
		Department EL PD		Title UICIT_PL_8_KIT					Doc-Key / ECM-Nr. DS00239314
		HARTING D-32339 Espelkamp							Type TB