


Product data sheet

179 N-8-2700/296

EAN-No. 4000896220298



296-pieces · 8 Drawers total

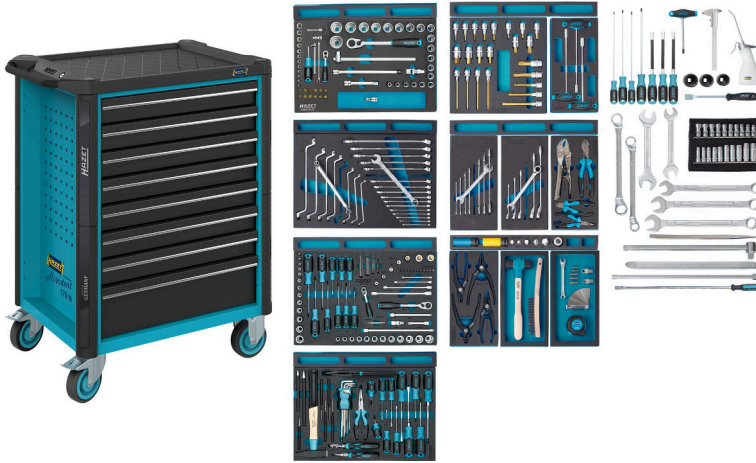

Application:

Efficient, mobile organisation of tools

- **MERCEDES-BENZ** tool trolley
- 7 flat drawers and 1 high drawer
- Includes 296-piece tool assortment in Safety-Insert-System soft foam insert

Work areas

- Much larger storage and work areas in plastic (179N) or stainless steel (179NX)
- Fully sealed work surface protects inside of trolley from leaking liquids
- Interfaces integrated in the work area for accessories such as laptop holders and top modules

Body / Pull-handle

- Extremely robust design thanks to dual-wall structure
- Complete welded construction of the entire body for tough daily workshop use
- Optimised, yielding edge protection on all four corners with real impact protection thanks to internal damping concept
- Ergonomically optimised pull handle for better manoeuvrability

Locking concept

- Ergonomically arranged side lock position for better operability protects keys and lock against damage
- Highly secure closing system with central locking technology for optimum protection of your property
- 2-stage locking
 - Central locking, lockable with cylinder lock and 2 folding keys
 - Mutual drawer locking for minimum tilting risk

Drawer concept

- Self-closing and reciprocal locking of the drawers prevents unwanted opening
- 100% sliding-out with ball-bearing telescopic slides
- Drawer design for optimum use of the interior
- Drawer fronts for optimised handling
- Dirt-resistant drawer coating for easy cleaning

High performance chassis

- Large wheels with high loading capacity, precision ball bearing and dual rounded rim in the pivot bearing, easy manoeuvrability, even with high dynamic load
- 2 swivel castors with dual brake:
 - Braked castors prevent rolling away
 - Braked swivel bearings prevent the swivel castors from turning, e.g. on inclined surfaces
- Protective ring prevents dirt and threads from getting in

179 N-8-2700/296

EAN-No. 4000896**220298**

- Elastic castors enable smooth movement

Assistant[®] **179N-6 – 9:**

- Solvent-resistant plastic work surface
- Metal handle, powder coated in black

Assistant[®] **179NX-6 – 8:**

- Stainless steel work surface
- Extra protection through high-quality plastic end caps
- Brushed stainless steel handle
- Total loading capacity (dynamic): 540 kg
- Loading capacity (static): 1000 kg
- Loading capacity of high drawer: 25 kg
- Colour: HAZET blue
- Tool trolley Made in Germany
- Dimensions: 785 mm x 518 mm x 1020 mm
- Net weight: 87.2 kg
- Drawers, flat: 7 × 81 x 522 x 398 mm
- Drawers, high: 1 × 166 x 522 x 398 mm
- (Drawer) size for plastic drawer insert: 3/3+
- Worktop: Plastic, resistant to solvent, with integrated storage wells
- Number of fixed castors: 2 (Ø 125 mm)
- Number of swivel castors: 2 (Ø 125 mm)
- Number of tools: 296

Order Number

179 N-8-2700/296

 


179N-8



163-53/75N

,
 ,
 ,
  •
 ,
 ,
 ,

163-30/25



600N • 

6 • 7 • 8 • 9 • 10 • 11 • 12 •

13 • 14 • 15 • 16 • 17 • 18 •

19 • 21 • 22 • 24

630 • 

$6 \times 7 \bullet 8 \times 9 \bullet 10 \times 11 \bullet$
 $12 \times 13 \bullet 14 \times 15 \bullet 16 \times 17 \bullet$
 $18 \times 19 \bullet 21 \times 22$

609 • 
E6, E8 • E10, E12 • E14,
E18 • E20, E24



811T • 

T6 • T7 • T8 • T9 • T10 •

T15 • T20 • T25 • T27 • T30

850E •  •  1/4"

E4 • E5 • E6 • E7 • E8



863HPB • 6.3 1/4"

880 •  •  $\frac{3}{8}$

10 • 11 • 12 • 13 • 14 • 15 •

16 • 17 • 18 • 19 • 21 • 22

880E •  •  3/8
E10 • E11 • E12 • E14

8802 •  • 
T40 • T45



8816HP • 10 3/8



8820 • 10 3/8 • 10 3/8

8821 • 10 3/8 • 10 3/8
8821-10 • 8821-3 • 8821-6

900E •  •  1/2
E16 • E18 • E20 • E24

992 •  •  1/2
T50 • T55 • T60

2115 • 
T6 • T7 • T8 • T9 • T10 •
T15 • T20 • T25 • T27 •
T30 • T40



2223LG •  •  6.3^{1/4}
T25

2223N • • 6.3 1/4"
T6

2223N •  •  •  6.3 1/4

T7H • T8H • T9H • T10H •

T15H • T20H • T25H •

T27H • T30H • T40H

2250-1 •  1/4" •  1/4"

2250-2 •  1/4" •  3/8"

Product data sheet

179 N-8-2700/296

EAN-No. 4000896220298



811F • ●

6 • 7 • 8

450N • ●

24 x 27 • 30 x 32

600N • ●

27 • 30 • 32

612 • ●

10 x 11

630 • ●

24 x 27 • 30 x 32

650-20



811LGT • ●

T15 • T20 • T25 • T30

824 • —

0.5 x 23

828-T • ●

T45

880G/10H • ● • 10 3/8

880G • ● • 10 3/8

10 • 11 • 12 • 13 • 14 • 15 •

16 • 17 • 18 • 19

880TZ/10H • ● • 10 3/8

880TZ • ● • 10 3/8

10 • 11 • 12 • 13 • 14 • 15 •

16 • 17 • 18 • 19

900SZ • ● • 12 1/2

32 • 34 • 36

918-23 • 12 1/2 • 12 1/2



1015/2 • ● 20 3/4



1014



1015-1 • ● 20 3/4



1952-35



1976



2130

2147



2154-10



2154N-5



2160

2165-2

2211 • ○ • ● 1/4

M4 • M5

2212 • ○ • ● 1/4

M10 • M6 • M8



6420B • 3/4 • 1/2



6420C • 3/4 • 1/2