

IZTP, High-voltage Power Supply Module IZTP40

Datasheet


General series information

- IZTP40: Standard type / IZTP41: AC type / IZTP42: Dual AC type.
- High-voltage power supply module separated from the bar.
- Easy mounting and removal using connector.
- Can be mounted separately from the controller or other high-voltage power supply modules.
- Weight: 800 g (IZTP40/41) & 1590 (IZTP42).
- DIN rail mounting bracket available.


Standard specifications

Model	40 (Standard type, IZTB40)
Type	Transistor Input/Output
DIN Rail Mounting Bracket	None
Maximum ambient temperature	40 °C
Minimum ambient temperature	0 °C
Approvals	CE
Power supply	24 VDC $\pm 10\%$
Material	Cover: ABS, Aluminium
Ambient humidity	35 to 80%RH (No condensation)
Weight	0.800 Kg

Dimensions

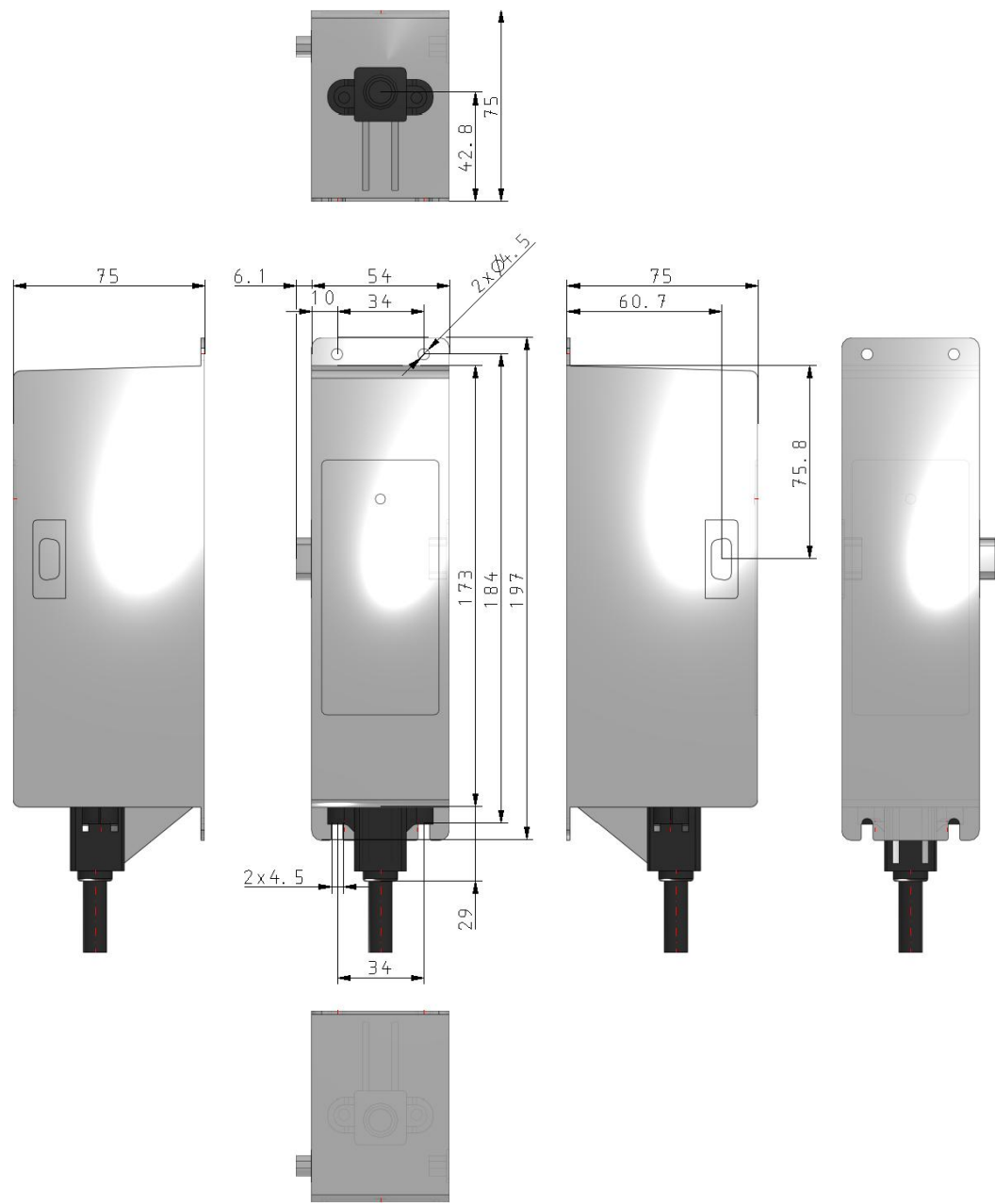

Constructions

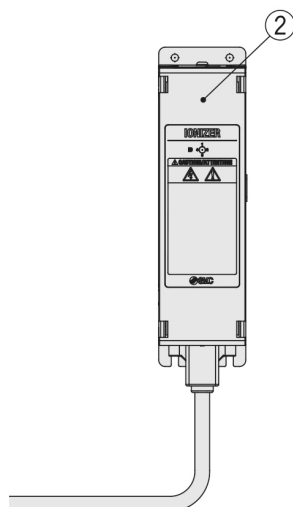

No.	Description
2	High voltage power supply module

Additional information

Catalogue	IZT40-41-42-43-D_EU.pdf
Declaration of conformity	newDoC_Izt_TF122006EN.pdf newDoC_IzX_TFV0004EN.pdf
Installation manuals	IM_IztX_TF2Z267EN.pdf
Operation manuals	OM_Izt-L_OMZ0045EN-A.pdf OM_Izt45_DOC1076325EN.pdf OM_Izt44_DOC1076323EN.pdf OM_Izt41-42-L_OMT0049EN-E.pdf