


## Leitz IQ OptiMax Home Office 225 Micro Cut Paper Shredder Security P5 15L - White

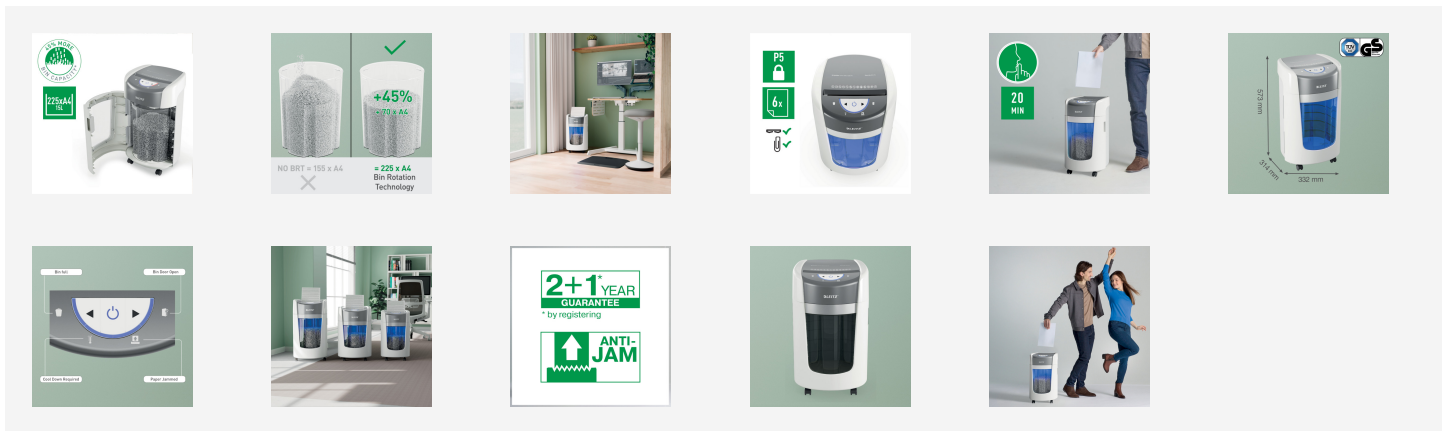

The Leitz IQ OptiMax home office shredder offers an innovative, stylish shredding solution, delivering exceptional document security and peace of mind. This high-security DIN P5 paper shredder effortlessly shreds up to 6x A4 sheets at a time into micro-cut pieces, making it an ideal small shredder for personal and home office use. Featuring unique Bin Rotation Technology (BRT), the Leitz shredder maximizes bin capacity by +45%\*. The rotating bin ensures flat, even paper distribution, preventing paper peaks and allowing an additional 70x A4 sheets to be shredded before needing to empty. With BRT, there's no need to remove or shake the bin — the 'bin full' indicator activates only at 100% capacity. The 15L bin holds up to 225 x A4 sheets, illuminated by a stylish blue light during use for an enhanced shredding experience. An intuitive LED display provides clear warning indications for bin full, door open, overheat, and overload, ensuring smooth, hassle-free operation. Designed for home workspaces, the Leitz IQ OptiMax 225 office shredder offers ultra-quiet performance to minimize disruption, making it perfect for shared living spaces. Its sleek, compact design blends effortlessly into any room, fitting easily into smaller areas without sacrificing performance. With 20 minutes of continuous runtime, this shredding machine delivers reliable, secure shredding for daily document disposal. White colour.

\*Leitz IQ OptiMax 225 tested with and without bin rotation technology.



## Attributes

- Shreds up to 6x sheets of A4 paper (80gsm) in just 6 seconds, into high security P5 micro cut pieces.
- Unique Bin Rotation Technology (BRT) maximizes bin capacity +45%\* and significantly reduces mess when emptying.  
\*Leitz IQ OptiMax 225 tested with and without bin rotation technology.
- Generous 15L bin capacity holds up to 225x A4 sheets before it needs to be emptied; +45% more capacity compared to no BRT (+70 x A4 sheets).
- Intuitive LED display with warning indications for bin full, door open, overheat and overload.
- Ultra quiet operation - for a calm working environment (when using Leitz oil papers regularly)
- Effortlessly shreds staples and paper clips, no need to remove them first.
- Continuous 20-minute run time, perfect for demanding personal and small office use.
- Anti-jam technology means that the shredder automatically stops and reverses the paper out when too much paper is inserted.
- The space-saving circular design fits neatly into corners and tight spaces to maximize your workspace.
- Easy to move across locations thanks to four high quality castor wheels.
- 2+1 years guarantee - register to get your extra year

## Specifications

Number	83581000
Colour	white
Dimensions (W x H x D)	332 x 573 x 314 mm
Cut Type	Micro Cut
Maximum Slot Entry Width (mm)	223
Run Time From Cold (min)	20
Run Time/Cool Down Time (min)	60
Shredded Particle Width mm	2x15
Security Level	P-5
Cutting Capacity sheets (80gsm paper)	6
Container/collection volume in l	15
Shreds	Staples and paper clips
Period of Warranty (Years)	2 + 1 year
Shredder Maintenance	Oil Sheets
Shredder Bin	Bin Window, Unique Filling Technology, Revolving, Backlit
Shredder Features	Wheels, Jam Free Technology, Touch Control
Weight	10000 g
Pallet quantity	9
EAN code	4002432142422