


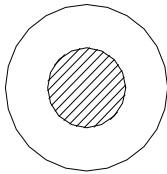

Product Name:	MIL-W-16878/4 26AWG
Product Discription:	MIL-W-16878/4 26AWG
Specification No.:	
Customer's Name:	

Description				
Rated Voltage:	600V			
Rated Temperature:	200℃			
Reference Standard:	MIL-W-16878/4			
Cross Section				
				
Marking				
No marking on the cable jacket				
Applications				
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.				
Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Danniel	Jason	19/05/2015
Construction				
Conductor	Stranded Sliver plated copper			
Size(AWG)	26			
Construction(±0.008mm)	19/0.10			
Stranded Dia.(mm)Ref.	0.5			
Insulation Material	PTFE			
Insulation Color	ANY COLOR			
Ave Thickness(mm)	0.25			
Insulation Dia.(±0.08mm)	0.99			
Remark: 8775446 Red 8775443 Blue 8775430 Black 8775440 White 8775434 Brown				
Characteristics				Customer Approve
Test Item		Standard Value		Seal & Stamp
Test Material		PTFE(ROHS)		
Insulation resistance(20℃ MΩ*m		1000		
Vol. Tesr(AC.V.60S) (V)		2000		
Flammability Test		VW-1		
Max.DC Resistance(20℃ Ω/km)		122.37(MAX)		
Signature:				
Date:				