

SAC-3P-M 8Y/2XM 8FS VP

Order No.: 1696222

<http://eshop.phoenixcontact.de/phoenix/treeViewClick.do?UID=1696222>

Y-distributor M8, with female connector M8, 3-pos. connector (parallel)

Commercial data

GTIN (EAN)	4017918182403
sales group	D116
Pack	5 pcs.
Customs tariff	85366990
Weight/Piece	0.01061 KG
Catalog page information	Page 104 (PC-2009)

Product notesWEEE/RoHS-compliant since:
11/29/2006

<http://www.download.phoenixcontact.com>
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

Technical data**General data**

Rated current at 40°C	4 A
Rated voltage	60 V
Number of positions	3
Volume resistance	≤ 5 mΩ
Insulation resistance	≥ 10 GΩ
Ambient temperature (operation)	-25 °C ... 90 °C

General characteristics

Standards/regulations	M8 male connector IEC 61076-2-104
Coding	A - standard
Surge voltage category	II
Pollution degree	3
Degree of protection	IP65/IP67
Contact material	CuZn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material of grip body	TPU, hardly inflammable, self-extinguishing
Material, knurls	Zinc die-cast, (nickel-plated)
Sealing material	NBR
Status display	No

Certificates / Approvals




Certification


CUL Listed, UL Listed

Diagrams/Drawings


Dimensioned drawing

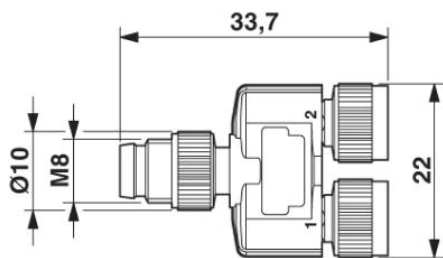

Schematic diagram

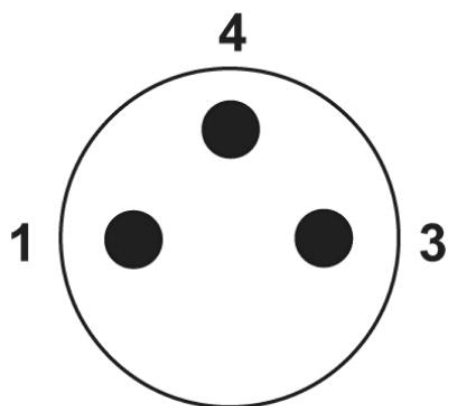

Pin assignment M8 plug, 3-pos., view male side

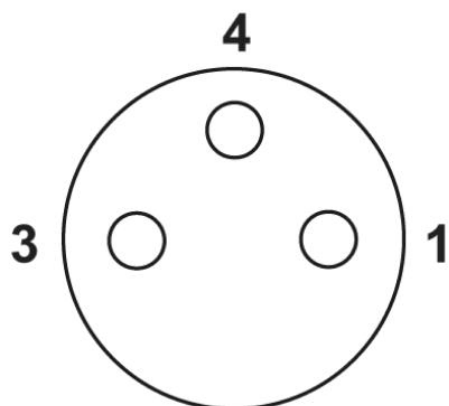

Pin assignment M8 socket, 3-pos., view female side

Address

PHOENIX CONTACT Ltd
Halesfield 13
Telford Shropshire TF7 4PG,GB
Phone 01952 681 700
Fax 01952 681 799
<http://www.phoenixcontact.co.uk>



© 2010 Phoenix Contact
Technical modifications reserved;