


19-in. Rack Cabinet Components and Accessories

Rack Cabinet Mobile Base

Constructed of die-cast aluminum finished with RAL 7030 stone gray textured polyester powder paint, the base fastens to the underside of the frame and provides integral mounting of furnished casters or optional adjustable feet. Base extends beyond the front and rear of 600mm cabinet to provide enhanced stability. Front and rear top surfaces of base have 3.0mm thick light gray rubber mats. Four casters provide load-bearing capacity of 1100 lbs. (499 kg). Casters and mounting hardware are furnished.


Catalog Number	Fits Cabinet
EERMB	600 x 600 and 600 x 800

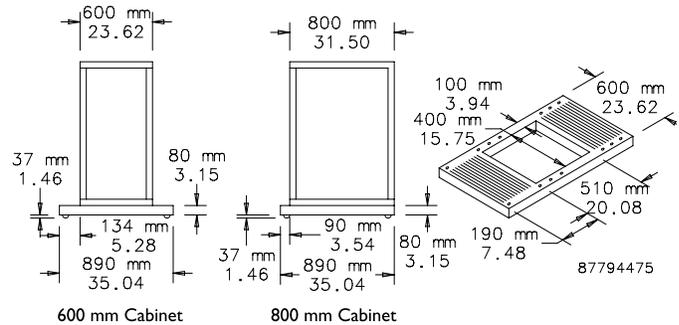

Rack Cabinet Casters and Adjustable Feet

Castors, two locking and two non-locking, mount directly to the bottom of the frame. The castors elevate the cabinet 110mm (4.33 in.). Castors are made of black polyamide material. A set of four castors will support a maximum load of 1100 lbs. (499 kg). Adjustable feet with ball and socket construction fit into the bottom of the cabinet frame or into the mobile base. Adjustable from 17mm to 35mm (0.67 in. to 1.38 in.) high. Four feet will support a maximum load of 880 lbs. (399 kg).


Catalog Number	Description
EERAFT	Set of four adjustable feet
EERCK	Set of four castors

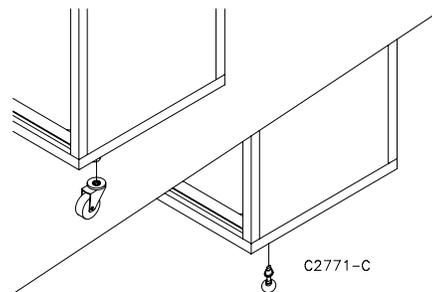

Grounding Kit

Includes five copper wires 4mm² diameter with ring terminals on both ends. Wires, 170mm (6.69 in.) long, have striped green / yellow PVC insulation. Kit includes toothed washers and bolts to attach wires to frame uprights. Grounding kit meets VDE 0160 and VDE 0411 part 100.


Catalog Number	Description
EERGDK	5 wires and hardware

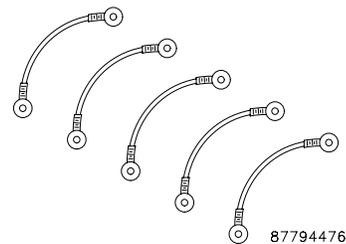

Rack Cabinet Joining Kit

Joining Kit connects two frames side-to-side once the side panels have been removed. Kit includes spacers and bolts as well as strips of foam gasket.

Catalog Number	Use with Cabinet
EERGK38U	43U maximum
EERGK34U	34U maximum

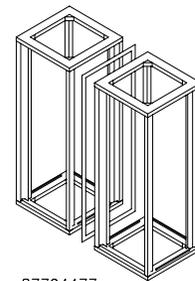

Rack Cabinet Slide Rails

Used to support heavy 19 in. subracks installed in a frame. Rails attach horizontally to openings on each side of a frame. Mounting holes are slotted to provide vertical adjustment. Flat surface of rails have slotted holes for attaching equipment if necessary. Made of 2mm steel with a plated finish. Furnished in pairs with mounting hardware included. Maximum load capacity is 88 lbs. (39.9 kg) per pair.

Catalog Number	L (mm)	L (in.)	Fits Cabinet
EERSR60	424	16.69	600mm deep
EERSR80	624	24.57	800mm deep

