

Datasheet

RS Pro Nut Drivers


EN



Product feature:

DIN 3125, ISO 2236

- 25 mm deep hexagon socket for long threaded bolts
- Chrome Vanadium steel shaft
- Matt chrome finish
- Softgrip handle

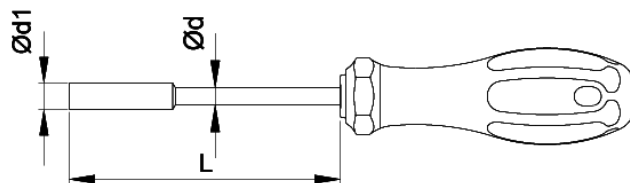

RS CODE NO	CODE NO	mm	Ød1 mm	Ød mm	L mm	mm	gr
1829730	F20-040-125RS	4.0	7.0	7.0	125	100	90
1829731	F20-050-125RS	5.0	8.0	7.0	125	100	92
1829732	F20-055-125RS	5.5	9.0	7.0	125	100	96
1829733	F20-060-125RS	6.0	9.0	7.0	125	100	96
1829734	F20-070-125RS	7.0	11.0	7.0	125	110	116
1829735	F20-080-125RS	8.0	12.0	7.0	125	110	118
1829736	F20-090-125RS	9.0	13.0	7.0	125	110	120
1829737	F20-100-125RS	10.0	14.0	7.0	125	110	124
1829738	F20-110-125RS	11.0	16.0	8.0	125	120	160
1829740	F20-120-125RS	12.0	17.0	8.0	125	120	166
1829741	F20-130-125RS	13.0	18.0	8.0	125	120	168