


REF : 2XX0 B

TRANXALARM® flexible alarm cable

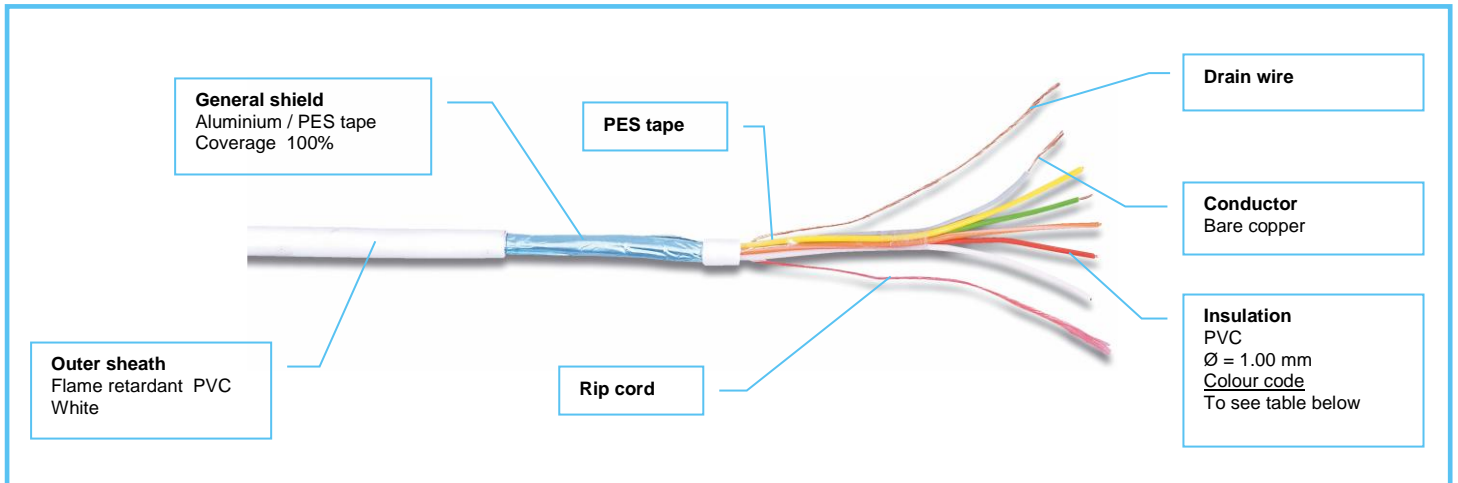

PRODUCTS INFORMATIONS

Application

The 0.22 mm² series is constituted by flexible multi-conductors cables.

Insulation colour code

1	White	11	Dark blue
2	Red	12	Pink
3	Yellow	13	White / Brown
4	Green	14	White / Violet
5	Grey	15	White / Green
6	Orange	16	White / Blue
7	Light blue	17	White / Grey
8	Brown	18	White / Yellow
9	Violet	19	White / Black
10	Black	20	White / Red

Electrical properties

Working voltage : **200 V**

Test voltage : **1200 V**

Characteristics



.....Flame behaviour : IEC 60332-1 or NF C 32-070 Cat C2



..... Working temperature : - 10°C → + 70°C



.....Minimum bending radius: 10 x Ø



 



..... According to RoHS standard

REF : 2XX0 B

TRANXALARM® flexible alarm cable

Products references

 REF	 nxmm ²	 mm±/-10% ← ext.	 Kg/Km
2020 B	2 x 0.22	3.10	15
2040 B	4 x 0.22	3.80	25
2060 B	6 x 0.22	4.40	36
2080 B	8 x 0.22	4.70	51
2100 B	10 x 0.22	5.50	60
2140 B	14 x 0.22	5.90	73
2200 B	20 x 0.22	6.70	113