


Features

- Length: 1m
- Power: 240W
- Data rate: 40Gbps
- E-Marker chip

RS PRO 1m USB4 40Gbps EPR Cable

RS Stock No.: 0839495

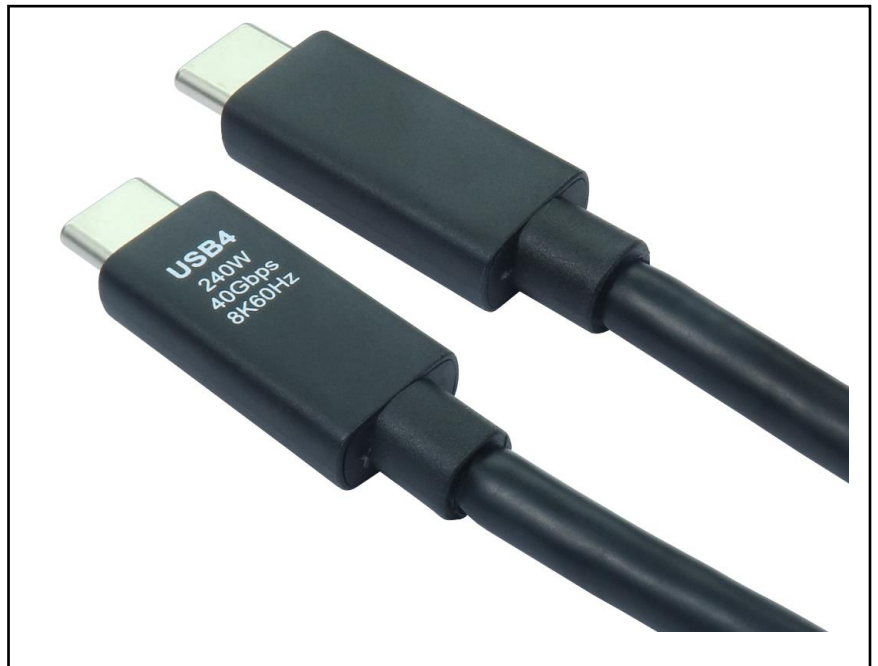

RS Professionally Approved Products bring to you, professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

USB4™ is the most recent update in the evolution of USB. The maximum bandwidth is now 40Gbps, double the previous best spec of 20Gbps (USB3.2 Gen 2x2). It is based on Thunderbolt 3 technology ensuring greater compatibility with all USB Type C and Thunderbolt 3 devices.

This cable supports Extended Power Range at 240W.

General Specifications


USB Type	USB4 40Gbps
Connector A	USB-C
Connector A Gender	Male
Connector B	USB-C
Connector B Gender	Male
Connector Style	Plug, straight
Data Transfer Rate	40Gbps
Outer Sheath Material	ABS
Sheath Colour	Black
Connector Plating	Nickel
Length	1m
Power	240W EPR

Approvals

Standards Met	CE UKCA ROHS REACH
---------------	--------------------

Similar Products

Stock No.	Brand	Product Name	Length	Connector A	Connector B
0839500	RS PRO	USB4 20Gbps EPR Cable	1m	USB-C (M)	USB-C (M)
0839500	RS PRO	USB4 20Gbps EPR Cable	2m	USB-C (M)	USB-C (M)
0839495	RS PRO	USB4 40Gbps EPR Cable	1m	USB-C (M)	USB-C (M)

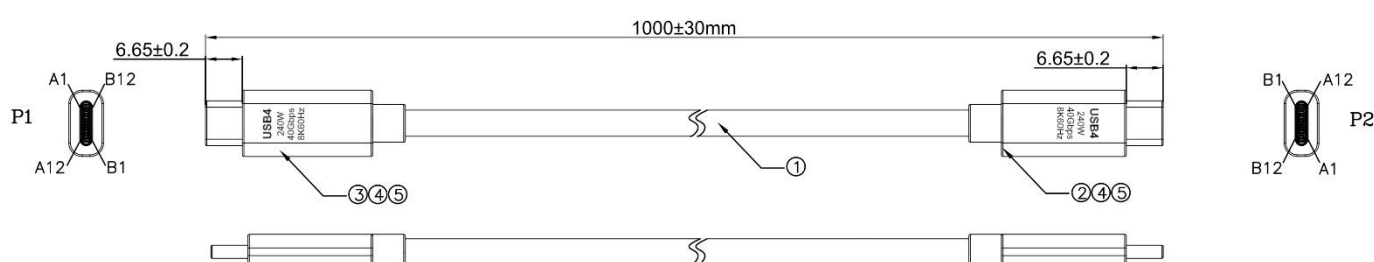

5	USB4 SHELL~PC+ABS~BLACK	2	PCS
4	TPE~BLACK	10	G
3	USB4~CONNECTOR~WITH IC~NI PLATED	1	PCS
2	USB4~CONNECTOR~WITHOUT IC~NI PLATED	1	PCS
1	30AWG*4P+34AWG*1P+34AWG*4C+24AWG*1C+EAS(95%TC)~OD:5.1MM~BLACK~TPE	1.0	m
NO.	DESCRIPTION	Q'TY	UNIT

