

RJ45 bending protection sleeve - VS-08-KS-H/GY - 1654743

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

RJ45 bend protection sleeve, for pin inserts VS-08-ST-H11-RJ45 and VS-08-ST-H21-RJ45, for cable cross section up to 7 mm, color: gray



Key commercial data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 017918 977801
Weight per Piece (excluding packing)	2.19 g
Custom tariff number	39269097
Country of origin	China

Technical data

Mechanical characteristics

External cable diameter	7 mm
Color	gray

Ambient conditions

Ambient temperature (operation)	-40 °C ... 80 °C
Degree of protection	IP20

Material data

Inflammability class according to UL 94	V0
Housing material	PA

Classifications

eCl@ss

eCl@ss 4.0	27140906
eCl@ss 4.1	27140906
eCl@ss 5.0	27140915

RJ45 bending protection sleeve - VS-08-KS-H/GY - 1654743

Classifications

eCl@ss

eCl@ss 5.1	27140915
eCl@ss 6.0	27140915
eCl@ss 7.0	27439224
eCl@ss 8.0	27439224

ETIM

ETIM 2.0	EC000307
ETIM 3.0	EC001680
ETIM 4.0	EC001680
ETIM 5.0	EC001680

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Accessories

Accessories

Male insert

RJ45 male insert - VS-08-ST-H11-RJ45 - 1652716



RJ45 pin insert, CAT5e, 8-pos., shielded, IDC connection method, for litz wires AWG 27 ... 26, with strain relief

RJ45 male insert - VS-08-ST-H21-RJ45 - 1652729




RJ45 male insert, CAT6, 8-pos., shielded, IDC displacement connection, for litz wire AWG 25 ... 24 and solid wires AWG 24, with strain relief

Drawings

RJ45 bending protection sleeve - VS-08-KS-H/GY - 1654743

Dimensioned drawing

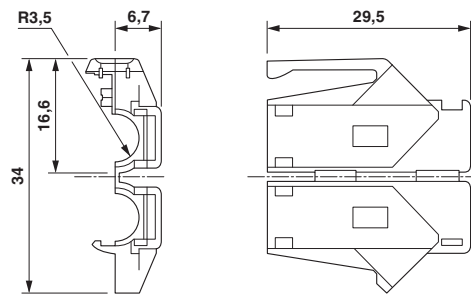

RJ45 bending protection sleeve