





Datasheet

ENGLISH

Stock No Twist & Flat Planar Cable

- 234411
- 234427
- 234382
- 234433
- 234398
- 234405

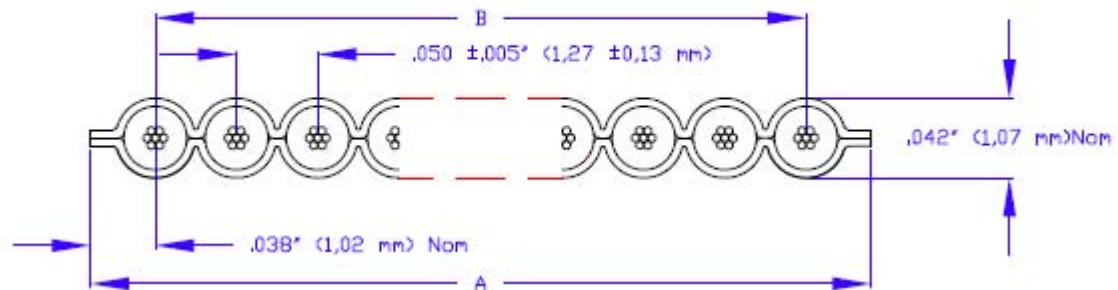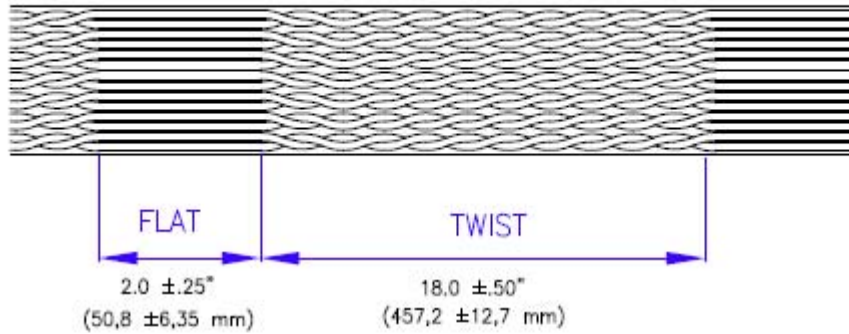

CONDUCTORS	28 AWG 7/36 tinned copper
INSULATION	0.10" PVC
LAMINATE	(2) .005" Clear PVC
COLOUR CODE	Brown, red, orange, yellow, green, blue, violet, grey, white, black, repeat.
TEMPERATURE RATING	105°C
IMPEDANCE	100 ohms
CAPACITANCE	15 pF/ft @ 1MHz

PROP DELAY	1.6 ns/ft
DC RES	65 ohms/1000 ft
CURRENT RATING	1.3A @ 10°C rise above ambient
VOLTAGE RATING	300 V
INSULATION RES	10 ohms 10ft minimum
APPROVALS	UL AWM style 20130 VW1

STOCK NO	NO OF PAIRS	NO OF CONDUCTORS	A SPAN	B SPAN"	B SPAN mm
234411	17	34	1.726" (43.84mm)	1.650 ±.015	41.91 ± 0.38
234427	20	40	2.026" (51.46mm)	1.950 ±.020	49.53 ± 0.51
234382	8	16	0.826" (20.98mm)	0.750 ±.015	19.05 ± 0.38
234433	25	50	1.205" (30.61mm)	1.150 ±.015	29.21 ± 0.38
234398	10	20	1.026" (26.06mm)	0.950 ±.015	24.13 ± 0.38
234405	13	26	1.326" (33.68mm)	1.250 ±.015	31.75 ± 0.38