



Product Datasheet


ENGLISH

CABLE SCR TWIST 2PR 100M

RS Article No: 812-4690



Cross Section:

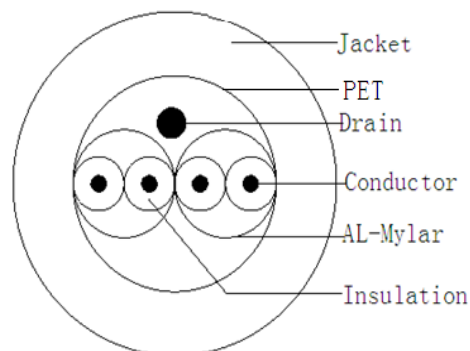

Cable Marking: 2PR 22AWG SCR TWIST 001M..100M

Construction:

Conductor: Tinned Copper

AWG: 22

Structure: 7/0.254

Conductor Dia. Nom. (mm): 0.76

Insulation: PP

Average Thickness(mm): 0.22

Insulation Dia. Nom.(± 0.20 mm): 1.20

Twisted: 2C

AL-Mylar(Each Pair AL Facing OUT)

Cabling: 2P

Drain: Tinned Copper

Structure: 7/0.20

PET: YES

Sheath: PVC

Average Thickness(mm): 0.50

Min point Thickness(mm): 0.40

Outer Dia. Nom.(± 0.30 mm): 4.50

Colour:

Insulation colours : Black-Red Green-White

Jacket color: Grey RAL7037

Electrical Characteristics:

Max. Conductor DC Resistance @20°C (ohms/km): 54.0