




Technical data

RNA4901LL/3AS

Needle roller bearing, machined-ring, without inner ring

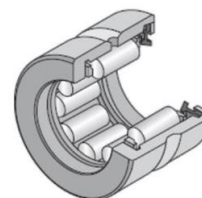

VISUAL (S)

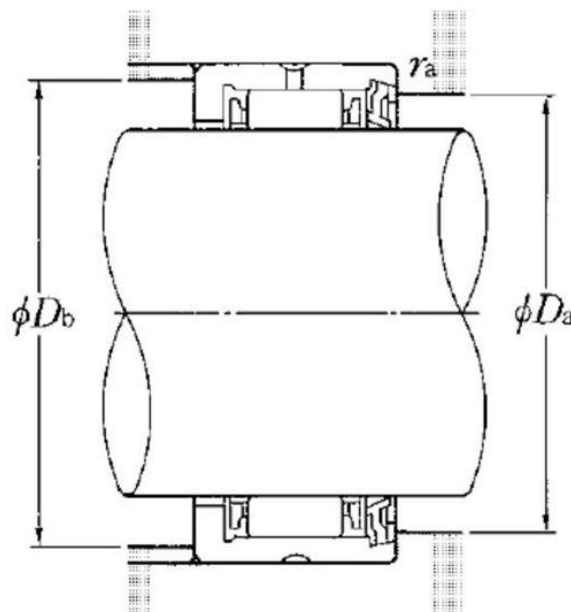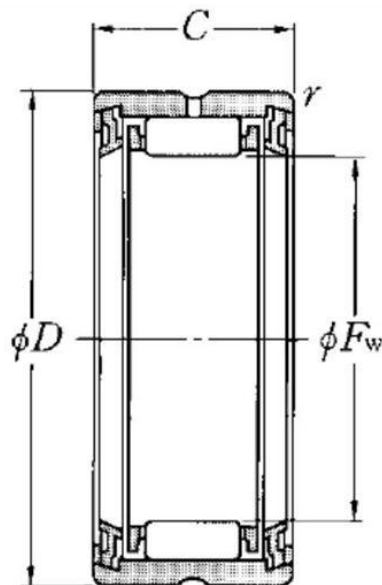

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	16 mm
D - External diameter	24 mm
C - Width of bearing, drawn cup or outer ring	13 mm
rs - Min fillet radius	0,3 mm
Lubrication hole on outer ring	Oui/Yes
k - Hole diameter	2,5 mm
Radial clearance class	CN
Precision class	P0



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

RNA4901LL/3AS

Needle roller bearing, machined-ring, without inner ring

PRODUCT DEFINITION

Mass	0,018 kg
------	----------

PRODUCT PERFORMANCE

Cr - Dynamic load rating	7,75 kN
C0r - Static load rating	9,7 kN
N lim - Grease lubrication limit speed	10000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	100 °C

ABUTMENT

Da max - Max shoulder diameter OR	18 mm
Db max - Max OR shoulder diameter	22 mm
ras max - Max shaft & housing fillet radius	0,3 mm

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	RNA4901LL/3AS
Image	NRBRNA49_LL_1.jpg, NRBRNA49_LL_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15