



SIVACON, door half, left, inspection window, IP55, H: 1800 mm, W: 400 mm, RAL 7035, protection class 1

Model			
product brand name		SIVACON	
product designation		Door half	
design of the product		Inspection window	
design of the surface		Powder-coated	
design of the product EMC version		No	
Protection class			
protection class IP		IP55	
operating resource protection class		safety class 1	
Appearance			
RAL color number		7035	
color		light grey	
Product details			
product component			
• ventilation			
• viewing door			
• door for disconnecter lock			
Mechanical Design			
height		1 800 mm	
width		400 mm	
opening direction of the door		left	
net weight		11 kg	
material		Steel/glass	
Approvals Certificates			
General Product Approval		Test Certificates	other



EG-Konf.



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------

[Miscellaneous](#)

Siemens
EcoTech



[Environmental Confirmations](#)

Further information
Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1840-2UT25-0BE2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1840-2UT25-0BE2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1840-2UT25-0BE2

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

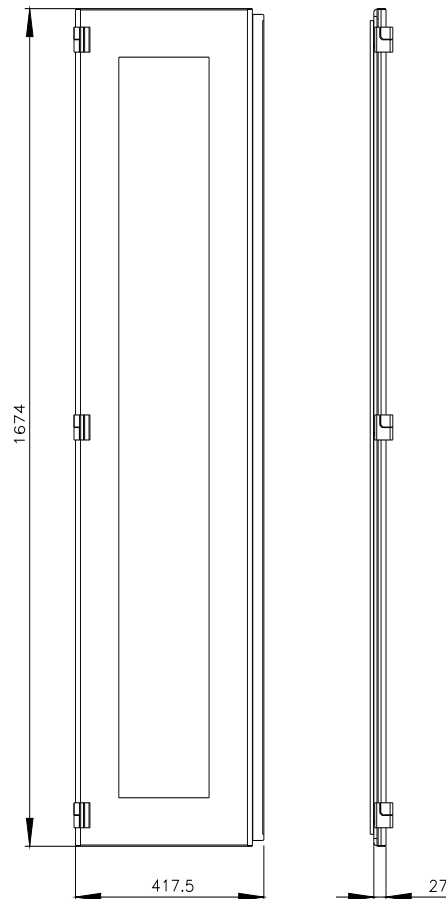

last modified:

4/13/2025 

