



Connectors > Terminal Blocks & Strips > PCB Terminal Blocks > Header Assembly: Wire-to-Board Connector, Spring Clamp, 7.5 mm pitch, 14.5A



Number of Positions: 3

Terminal Block Connector Type: **Receptacle**

Connector System: **Wire-to-Board**

Centerline (Pitch): **7.5 mm [.295 in]**

Number of Rows: 1

[All Header Assembly: Wire-to-Board Connector, Spring Clamp, 7.5 mm pitch, 14.5A \(7\)](#)

Features

Product Type Features

Terminal Block Connector Type	Receptacle
Connector System	Wire-to-Board
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	3
Number of Rows	1
Wire Entry Angle	180°
Wire Entry Location	Top

Electrical Characteristics

Operating Voltage	300 VAC
-------------------	---------

Body Features

Primary Product Color	Black
Product Orientation	Vertical

Contact Features

Contact Mating Area Plating Material	Gold (Au)
--------------------------------------	-----------



Contact Base Material	Copper Alloy
Contact Current Rating (Max)	12.7 A

Termination Features

Termination Method to Wire & Cable	Push-in
------------------------------------	---------

Mechanical Attachment

Connector Mounting Type	Cable Mount (Free-Hanging)
-------------------------	----------------------------

Housing Features

Housing Material	Thermoplastic
Centerline (Pitch)	7.5 mm[.295 in]

Dimensions

Wire Size	22 – 14 AWG
-----------	-------------

Usage Conditions

Operating Temperature Range	-30 – 105 °C[-22 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Circuit Application	Power & Signal
---------------------	----------------

Packaging Features

Packaging Method	Tray
------------------	------

Product Compliance

For compliance documentation, visit the product page on [TE.com](#)>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as



EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 3-2229803-1
D3950 HDR 3POS 1ROW X KEY

Also in the Series | Dynamic 3000 Series

Connector Contacts(94)

Connector Hardware(8)

Insertion & Extraction Tools(2)

PCB Headers & Receptacles(290)

PCB Terminal Blocks(27)

Power Contacts(94)

Rectangular Power Connectors(386)

Wire-to-Board Headers & Receptacles (290)

Customers Also Bought



TE Part #2305219-1
MICRO STACK HDR ASSY 9MM 0.1
GOLD



TE Part #1376133-2
DYNAMIC D-3500 HDR ASSY 4P



TE Part #1-2013519-3
DYNAMIC D3900 H-HDR ASSY 3P X
TYPE-A



TE Part #1-917337-5
DYNAMIC D-3 VERTI. HDR ASSY 2P
TYPE-A



TE Part #2305220-1
MICRO STACK HDR ASSY 20MM 0.1
GOLD




TE Part #1-917541-2
DYNAMIC D-5 S/ROW HDR ASY 4P H



TE Part #61907-1
187 FASTON TAB TPBR



TE Part #1903815-1
INDUSTRIAL USB REC ASSY R/A
2ROW

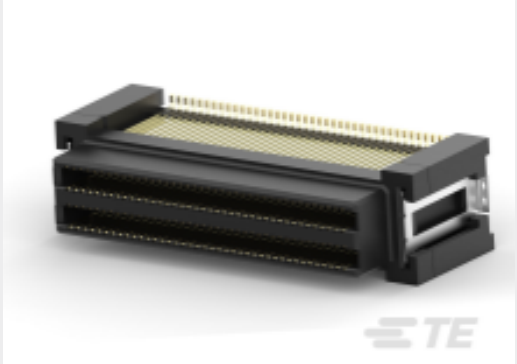

TE Part #2305217-1
MICRO STACK REC ASSY 0.1 GOLD



TE Part #3-5175475-1
CHAMP 050 B-T-B REC V W/LEG

Documents

Product Drawings

D3950 REC 3POS 1ROW X KEY MARKED

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_3-2229794-1_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_3-2229794-1_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_3-2229794-1_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



DYNAMIC SPRING CLAMP SERIES

English

DYNAMIC SPRING CLAMP SERIES

Japanese

Introducing TE's D3950 Series Connector

English

Product Specifications

Product Specification

English

Instruction Sheets

Instruction Sheet (non U.S.)

English

Agency Approvals

UL Report

English